

# UPGLCUCL

---

## Base Product

Ultra Low Loss (ULL) Singlemode LC/UPC to Unconnectorized Armored Pre-terminated Trunk Cable, 96-Fiber, Plenum

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Ruggedized fanout
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


<b>Connector A, quantity</b>	96
<b>Color, boot A</b>	Blue
<b>Color, connector A</b>	Blue
<b>Construction Type</b>	Ultra Low Loss (ULL) armored trunk/extension/cross-connect, indoor
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	LC/UPC
<b>Interface, Connector B</b>	Unterminated
<b>Jacket Color</b>	Yellow
<b>Total Fibers, quantity</b>	96

## Dimensions

<b>Cable Assembly Length Range (m)</b>	7 – 999
<b>Cable Assembly Length Range (ft)</b>	25 – 999

## Ordering Tree

# UPGLCUCL

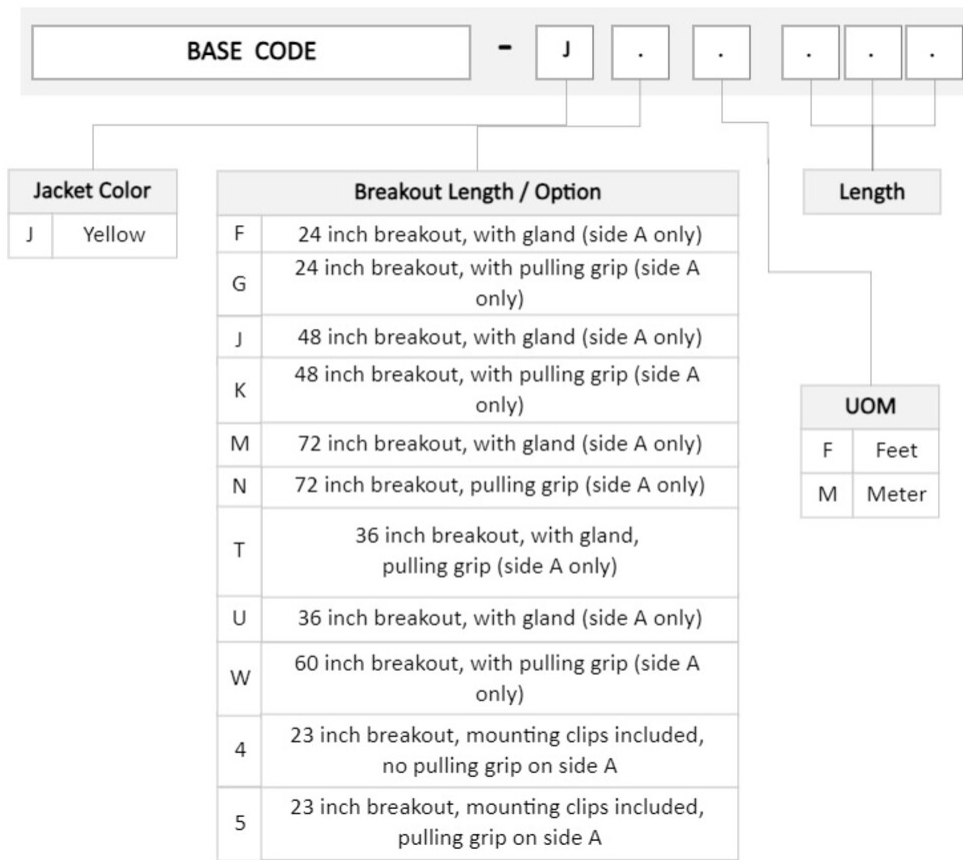

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2, TeraSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Indoor   Plenum

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

# UPGLCUCCL

---

## Included Products

- 760256105  
N-096-MZ-8G1-F12YL/20T/B2 – Fiber indoor cable, Riser/LSZH rated MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2/B2, 96 fiber, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860637435 – LC/UPC Connector, Singlemode, Blue, Short Boot