


760258357 | PPL-FA-5U-VCM

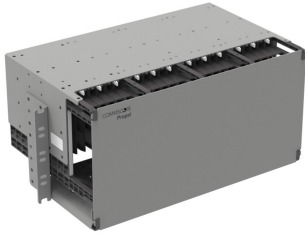

Propel 5RU front access fiber panel with cable trough for Propel XFrame. Accepts 24, 16 fiber or 48, 8 fiber Propel ULL modules, splice cassettes or 8 port/4 port adapter packs

- Panel comes with 24 carriers to allow for all front access using standard Propel components. Incoming cable and patch cords are routed at the front of the panel
- VCM (Vertical Cable Management) panels: With VCM panels, patch cords are routed straight down to a trough and over. This provides finger access for Moves, Adds and Changes
- For use with 8 fiber or 16 fiber Propel components

Product Classification

Portfolio	CommScope®
Product Type	Fiber patch panel
Product Brand	Propel
Product Series	PPL

General Specifications

Color	Gray
Interface, front	Unloaded
Rack Type	EIA 19 in
Rack Units	5
Shelf Movement	Fixed

Dimensions

Height	222 mm 8.74 in
Width	483 mm 19.016 in

Material Specifications

Material Type	Aluminum Steel
----------------------	------------------

Environmental Specifications

Safety Standard	UL
------------------------	----

760258357 | PPL-FA-5U-VCM

Packaging and Weights

Packaging quantity 1