


FID-LG-150M-01A-LG

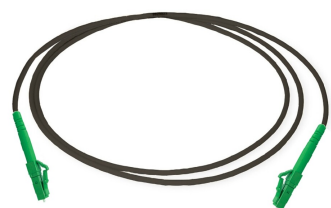

Fiber Optic Indoor/outdoor 3 mm Drop Cable Assembly, LC/APC-LC/APC, 150 M

Product Classification

Regional Availability	EMEA
Product Type	Fiber drop cable assembly
Product Series	FID
Ordering Note	For custom cable assembly lengths, please contact your local CommScope representative

General Specifications


Cable Type	Stapleable - Round
Connector A, quantity	1
Color, boot A	Green
Color, connector A	Green
Connector B, quantity	1
Color, boot B	Green
Color, connector B	Green
Interface, Connector A	LC/APC
Interface Feature, connector A	Male
Interface, Connector B	LC/APC
Interface Feature, connector B	Male
Jacket Color	Black
Total Fibers, quantity	1

Dimensions


Cable Assembly Length	150 m 492.126 ft
Cable Outer Diameter	3.0 mm (0.12 in)

Dimension Drawing


FID-LG-150M-01A-LG

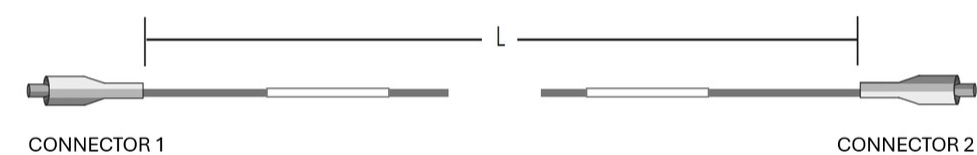

Ordering Tree

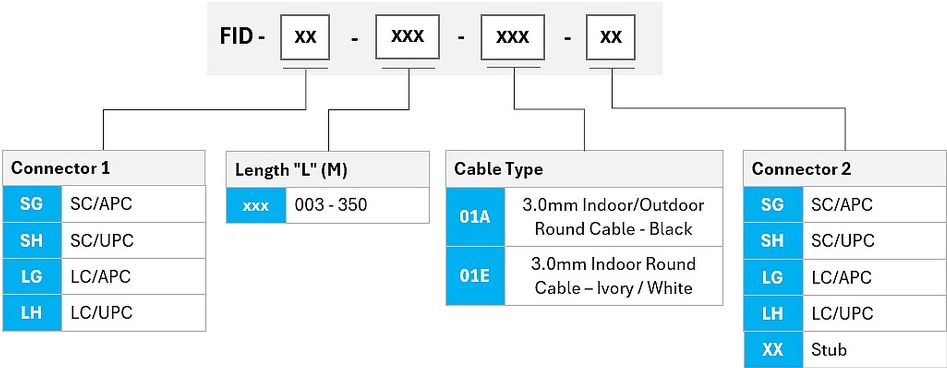

Representative Image

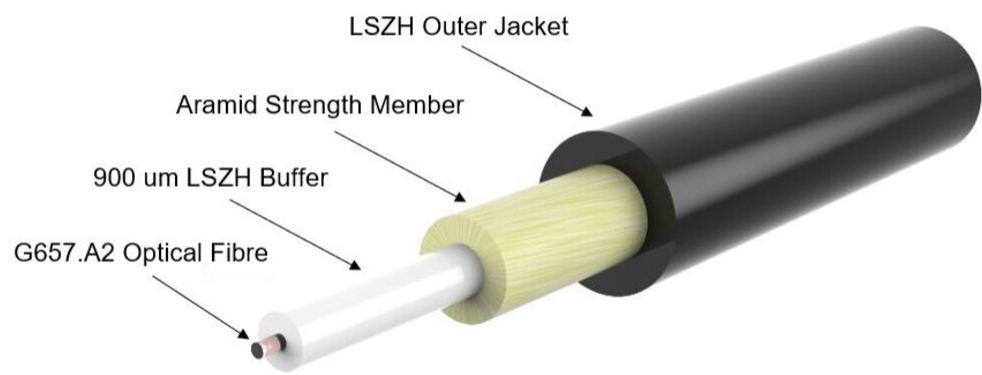

Material Specifications

FID-LG-150M-01A-LG

FID-LG-150M-01A-LG

ROHS

UK-ROHS

Compliant

Compliant



Included Products

810010113/DB
C-001-DN-8G1-M01BK/30D/D-UK00

–

Indoor/Outdoor Fiber Optic Drop cable, 1 Fiber G657 A2 0.9mm tight buffer. Breaking load Max 2000N. Suitable for installation under overhead power lines $\leq 11\text{kV}$, vertical clearance $\geq 1.8\text{m}$.