


760260216 | IFEB-SEAL-D-4-LAYER

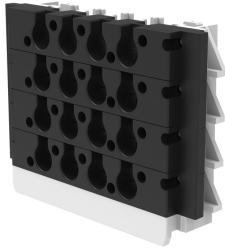

IFEB Fibre Optic Wrap around Distribution Cable Sealing Kit for for pigtails and cables with a diameter up to 7 mm, 4 layer, 16 ports

- Distrubtuion cable seal for IFEB-20
- For pigtail, patchcord & cable diamenters of 1.8mm to 7mm
- Indoor use only
- IEC-60529 IP50
- Cable retention max 25N per cable (15N fo cable < 3.0mm)

Product Classification

Regional Availability	EMEA
Portfolio	CommScope®
Product Type	Cable sealing
Product Series	IFEB-20

General Specifications

Cable Ports, quantity	16
------------------------------	----

Environmental Specifications

Installation temperature	-5 °C to +45 °C (+23 °F to +113 °F)
Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor
Flammability Rating	UL 94 V-0
Qualification Standards	IEC 60529, IP50 IEC 61753-1 Ed.2 2018 - Category C

Packaging and Weights

Included	Cable attachement 4 layer assembly (1) Protection Tape (1) Screw (1) Tie wrap (4)
Packaging quantity	1
Packaging Type	Box

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

760260216 | IFEB-SEAL-D-4-LAYER

ROHS Compliant

UK-ROHS Compliant

