


# 760260218 | IFEB-SEAL-D-8-LAYER

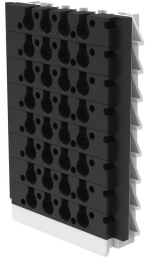

IFEB Fibre Optic Wrap around Distribution Cable Sealing Kit for for pigtails and cables with a diameter up to 7 mm, 8 layer, 32 ports

- Distrubtuion cable seal for IFEB-50
- For pigtail, patchcord & cable diamenters of 1.8mm to 7mm

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Cable sealing
<b>Product Series</b>	IFEB-50

## General Specifications

<b>Cable Ports, quantity</b>	32
------------------------------	----

## Environmental Specifications

<b>Installation temperature</b>	-5 °C to +45 °C (+23 °F to +113 °F)
<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Indoor
<b>Flammability Rating</b>	UL 94 V-0
<b>Qualification Standards</b>	IEC 60529, IP50   IEC 61753-1 Ed.2 2018 - Category C

## Packaging and Weights

<b>Included</b>	Cable attachment 8 layer assembly (1)   Protection Tape (1)   Screw (1)   Tie wrap (4)
<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Box

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

