


# 760260220 | IFEB-SEAL-F-2x15

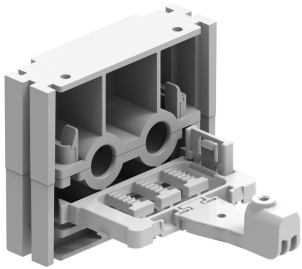

IFEB Fibre Optic Wrap around Feeder Cable Sealing Kit for up to 2 cables with a cable diameter of max 15 mm

- Feeder cable seal for IFEB-20
- For 2 cables, diameters of 7mm to 15mm
- Indoor use only
- IEC-60529 IP50
- Cable retention max 25N per cable
- Includes cable termination baseplate and strength member fixation (1)
- For additional cables IFEB-SEAL-F-ADD is required (ordered separately)

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Cable sealing
<b>Product Series</b>	IFEB-20

## General Specifications

<b>Cable Ports, quantity</b>	2
------------------------------	---

## Environmental Specifications

<b>Installation temperature</b>	-5 °C to +45 °C (+23 °F to +113 °F)
<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Indoor
<b>Flammability Rating</b>	UL 94 V-0
<b>Qualification Standards</b>	IEC 60529, IP50   IEC 61753-1 Ed.2 2018 - Category C

## Packaging and Weights

<b>Included</b>	Cable attachment baseplate (1)   Cable attachment strength member (1)   Cable seal 2x15 assembly (1)   Protection Tape (1)   Screw (2)   Tie wrap (2)
<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Box

## Regulatory Compliance/Certifications

Agency	Classification
--------	----------------

# 760260220 | IFEB-SEAL-F-2x15

---

CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

