


# OM412S42YAS2XS2X0000

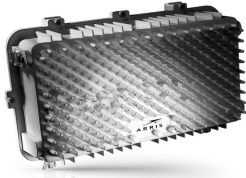

## Opti Max™ 1.2 GHz Deep OM4120 Optical Node, 4x4 HFC Segmentable

- \*Product complies with the Build America, Buy America Act (BABAA) requirements of the Infrastructure Investment and Jobs Act of 2021 (Pub. L. 117- 58, §§ 70901-70953), or is the subject of a waiver approved by the Secretary of Commerce or designee. Compliance requirements and waiver applicability vary based on government funding program. Check the laws and regulations for your specific program.

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Product Type</b>	Optical node platform
<b>Product Series</b>	OM4120
<b>Government Requirements</b>	Build America Buy America (BABA) compliant*

## General Specifications

<b>Location of Manufacturing</b>	Waived per BABA waiver for BEAD Program
----------------------------------	---

## Electrical Specifications

<b>Input Voltage Range, ac</b>	44–90 V
--------------------------------	---------

## Environmental Specifications

<b>Operating Temperature</b>	-40 °C to +60 °C (-40 °F to +140 °F)
<b>Relative Humidity</b>	5%–95%, non-condensing

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

