

CY2686-001 | OWB-S-NO-S22-NN-W-L



OWB Fiber Optic Wall Mount Fiber Box, 2 SC/APC adapters, no splicing, no splitters

- Compact sized with multiple cable entry point options
- Used as a premises connection device in FTTH networks
- Easy access via the combined hinge + latch design
- High sealing rate, UV resistant and UL compliant
- Slack storage (3 mtr) for drop- and premise connection cable

Product Classification

Regional Availability	Asia Australia/New Zealand Latin America North America
Product Type	Fiber wall box
Product Series	OWB


General Specifications

Functionality	Patching
Access	Front
Application	For cables with outer diameter 3 x 5.4 mm: 1 on top + 1 on bottom For cables with outer diameter up to 10 mm: each on both sides For cables with outer diameter up to 5 mm: 1 on rear + 4 on bottom
Enclosure Color	Gray
Front Cover Type	Hinged with latches
Interface	SC/APC
Lock Type	Ski latch and screw
Mounting	Wall
Port Capacity, maximum	4
Port, quantity	2

Dimensions

Height	209.8 mm 8.26 in
Width	173.74 mm 6.84 in
Depth	71.88 mm 2.83 in

Dimension Drawing

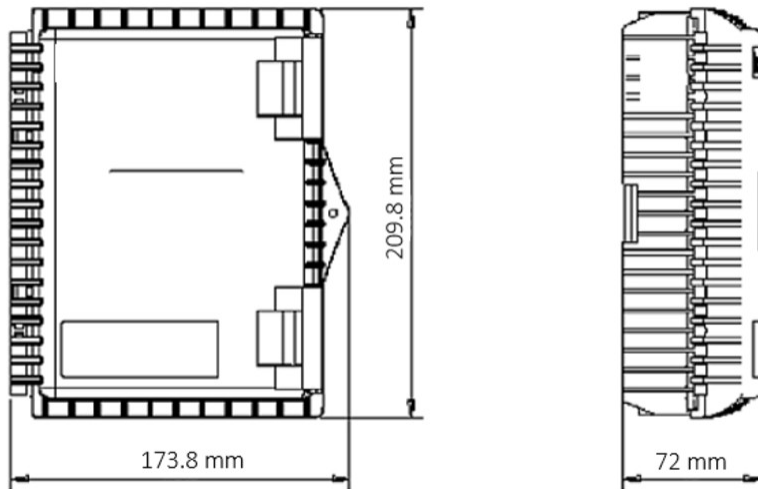

Material Specifications

Enclosure Material Type LSZH thermoplastic

Optical Specifications

Fiber Mode Singlemode

Insertion Loss, Terminal Connector, maximum 0.1 dB

Environmental Specifications

Installation temperature -5 °C to +45 °C (+23 °F to +113 °F)

Storage Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Environmental Space Outdoor

Flammability Rating UL 94 V-0

Qualification Standards IEC 60529, IP65

Packaging and Weights

Included Grommets

Packaging quantity 1

Packaging Type Box | Carton

Regulatory Compliance/Certifications

CY2686-001 | OWB-S-NO-S22-NN-W-L

Agency

CHINA-ROHS

REACH-SVHC

ROHS

UK-ROHS

**Classification**

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant