

FL2-6P8SC605R

FL2000 Fiber Optic Adapter-pack, with 6 singlemode LC/UPC duplex adapters, with pigtails, 5 meters

Product Classification

Regional Availability	North America
Product Type	Fiber adapter pack with pigtails
Product Series	FL2000

General Specifications


Application	For use with FL2 panels
Adapter Color	Blue
Adapters, quantity, front	6
Body Style	Duplex Straight orientation
Color, front	Putty white
Interface	LC/UPC
Pigtail Assembly Type	Color-coded, 900 μ m Pigtail bundle
Pigtails Included, quantity	12
Total Fibers, quantity	12
Total Ports, quantity, front	12

Dimensions

Height	27.94 mm 1.1 in
Width	149.86 mm 5.9 in
Pigtail Length	5 m 16.404 ft

Ordering Tree

FL2-6P8SC605R

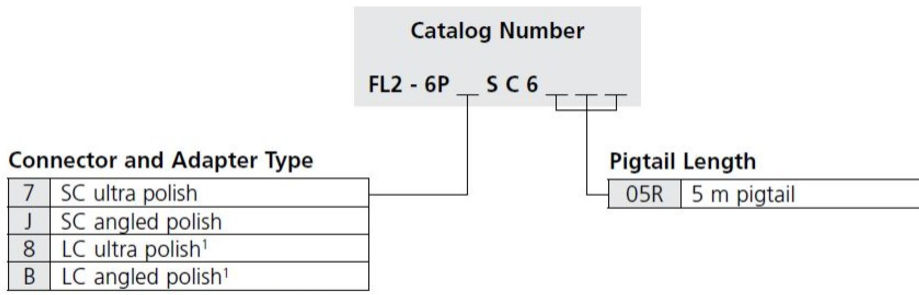

¹ LC 6paks are loaded with 12-fiber pigtails

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum	0.3 dB
Return Loss, minimum	55 dB

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

