

FMT-GRT070A00-A72P



FMT Fiber Termination Panel, with sliding tray, 72 SC/UPC, singlemode, 2RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FMT

General Specifications


Functionality	Patching
Body Style	Symmetrical
Color	Black
Color, front	Putty white
Interface, front	SC/UPC
Rack Type	EIA 19 in EIA 23 in
Rack Units	2
Shelf Movement	Sliding
Total Ports, quantity	72

Dimensions

Height	88.9 mm 3.5 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in

Ordering Tree

FMT-GRT070A00-A72P

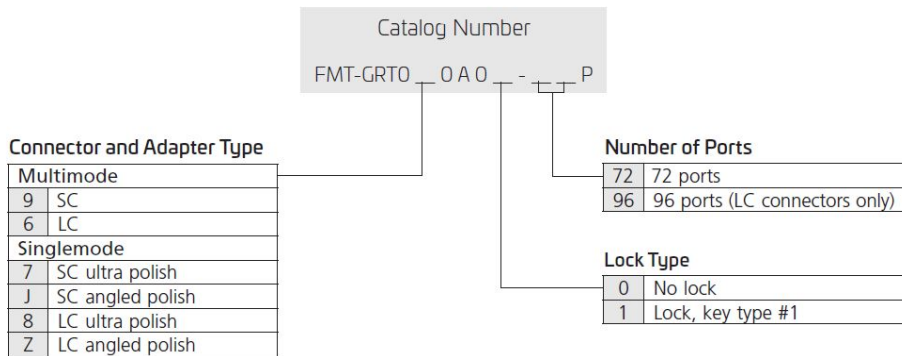

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

UK-ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant

