


FPS-CMPP2GJJ

FDH4000, 2X32 splitter, SC/APC

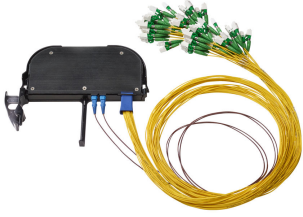

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Splitter module
Product Series	FDH 4000

General Specifications

Device Type	Plug-and-play module
Functionality	Splitting
Application	For use in FDH 4000 closures
Circuits, quantity	1
Distribution Type	2 x 32 splitter
Interface, Input	SC
Interface Feature, Input	APC
Interface, Output	SC
Interface Feature, Output	APC
Module Color	Black
Split Ratio	Symmetrical
Splitter, quantity	1

Optical Specifications

Directivity, minimum	60 dB
Polarization Dependent Loss, maximum	0.4 dB
Uniformity, maximum	2 dB
Wavelength Range	1260–1635 nm

FPS-CMPP2GJJ

Insertion Loss, Splitter, maximum	17.4 dB
Insertion Loss, Splitter, typical	16.2 dB
Return Loss, Splitter, minimum	55 dB

Packaging and Weights

Packaging quantity	1
---------------------------	---