


FPS-CMPP2MJJ

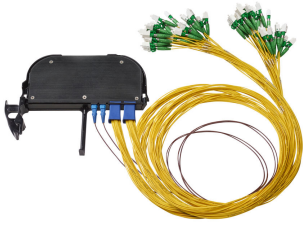

FDH4000, Dual 1X16 splitter, SC/APC

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Splitter module
Product Series	FDH 4000

General Specifications

Device Type	Plug-and-play module
Functionality	Splitting
Application	For use in FDH 4000 closures
Circuits, quantity	2
Distribution Type	1 x 16 splitter
Interface, Input	SC
Interface Feature, Input	APC
Interface, Output	SC
Interface Feature, Output	APC
Module Color	Black
Split Ratio	Symmetrical
Splitter, quantity	2

Optical Specifications

Directivity, minimum	60 dB
Polarization Dependent Loss, maximum	0.3 dB
Uniformity, maximum	1 dB
Wavelength Range	1260–1635 nm

FPS-CMPP2MJJ

Insertion Loss, Splitter, maximum	13.5 dB
Insertion Loss, Splitter, typical	12.8 dB
Return Loss, Splitter, minimum	55 dB

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted

