


1168156-ZZ | FL2-R970096A0-0A00-R

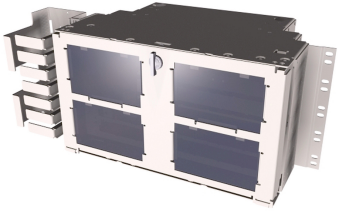

FL2000 Fiber Termination Panel, 96 SC/UPC, singlemode, 6RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	8
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Patching Capacity, maximum	96
Rack Type	EIA 19 in
Rack Units	6
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	96

Dimensions

Height	266.7 mm 10.5 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

1168156-ZZ | FL2-R970096A0-0A00-R

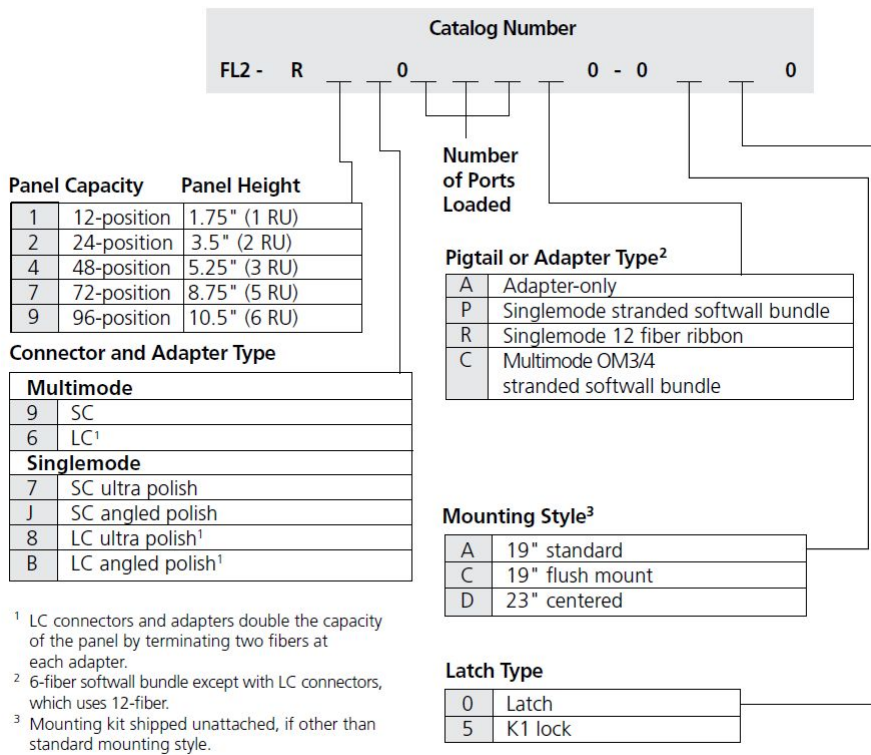

Material Specifications

Finish Powder coated
Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included Mounting hardware
Packaging quantity 1

Regulatory Compliance/Certifications

1168156-ZZ | FL2-R970096A0-0A00-R

Agency

Classification

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

