


FD3-MM288J00LABCAA

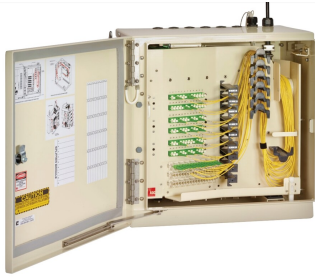

IFDH 3000 Indoor Fiber Distribution Hub, 288F, SC/APC, riser I/O LT 50' stub, 12F 100' stub feeder cable

Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	IFDH 3000

General Specifications

Access	Front
Adapters, quantity	288
Cable Type	Pigtails - Stranded
Color	Putty white
Distribution Cables, quantity	2
Fibers per Distribution Cable, quantity	144
Fibers per Feeder Cable, quantity	12
Front Door Type	Single hinged
Interface	SC/APC
Mounting	Wall
Port, quantity	288
Splitter Slots, quantity	18

Dimensions

Height	839 mm 33.032 in
Width	600 mm 23.622 in
Depth	427 mm 16.811 in
Cable Length	15.24 m 50 ft
Enclosure Size	Medium

Material Specifications

FD3-MM288J00LABCAA

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Environmental Space Indoor

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

