


# FD3-AC096J00U20P2

---

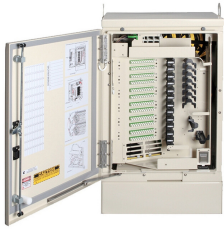

FDH 3000 Fiber Distribution Extra Small In-Hub Splice Cabinet, 96F, SC /APC, 0 spltr., LT pigtailed, heat-shrink fusion splice, 24F

## Product Classification

<b>Regional Availability</b>	North America
<b>Product Type</b>	Fiber distribution hub
<b>Product Series</b>	FDH 3000

## General Specifications

<b>Access</b>	Front
<b>Cable Type</b>	Microcable - Loose Tube
<b>Color</b>	Putty white
<b>Distribution Cables, quantity</b>	1
<b>Distribution Ports, quantity</b>	144
<b>Fibers per Distribution Cable, quantity</b>	96
<b>Fibers per Feeder Cable, quantity</b>	24
<b>Interface, Input</b>	SC
<b>Interface Feature, Input</b>	APC
<b>Mounting</b>	Pad
<b>Splitter Slots, quantity</b>	9

## Dimensions

<b>Height</b>	914.4 mm   36 in
<b>Width</b>	533 mm   20.984 in
<b>Depth</b>	355.6 mm   14 in
<b>Cable Length</b>	30.48 m   100 ft
<b>Enclosure Size</b>	Extra small

## Material Specifications

<b>Finish</b>	Powder coated
<b>Material Type</b>	Aluminum

# FD3-AC096J00U20P2

---

## Environmental Specifications

**Environmental Space** Above ground

## Packaging and Weights

**Packaging quantity** 1

**Packaging Type** Pallet

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

