


FD3-AJ576J00JBPP4

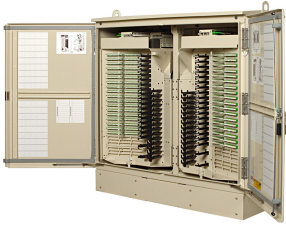

FDH 3000 Fiber Distribution Large Cabinet, 576F, SC/APC, no splitters, dielectric loose tube, 100 ft, 48F

Product Classification

| | |
|------------------------------|------------------------|
| Regional Availability | North America |
| Product Type | Fiber distribution hub |
| Product Series | FDH 3000 |

General Specifications

| | |
|--|-----------------------------|
| Access | Front and rear door |
| Cable Type | Dry Dielectric - Loose Tube |
| Color | Putty white |
| Distribution Cables, quantity | 4 |
| Distribution Ports, quantity | 576 |
| Fibers per Distribution Cable, quantity | 144 |
| Fibers per Feeder Cable, quantity | 48 |
| Interface, Input | SC |
| Interface Feature, Input | APC |
| Mounting | Pad |
| Splitter Slots, quantity | 48 |

Dimensions

| | |
|-----------------------|------------------------|
| Height | 1,238.25 mm 48.75 in |
| Width | 1,220.47 mm 48.05 in |
| Depth | 497.33 mm 19.58 in |
| Cable Length | 30.48 m 100 ft |
| Enclosure Size | Large |

Material Specifications

| | |
|----------------------|---------------|
| Finish | Powder coated |
| Material Type | Aluminum |

FD3-AJ576J00JBBP4

Environmental Specifications

Environmental Space Above ground

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Above maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

