


# FD3-AJ648J00GCBP4

---

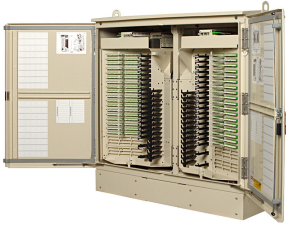

FDH 3000 Fiber Distribution Large Cabinet, 648F, SC/APC, no splitters, single armor loose tube, 100 ft, 48F

## Product Classification

<b>Regional Availability</b>	North America
<b>Product Type</b>	Fiber distribution hub
<b>Product Series</b>	FDH 3000

## General Specifications

<b>Access</b>	Front and rear door
<b>Cable Type</b>	Armored - Single Loose Tube
<b>Color</b>	Putty white
<b>Distribution Cables, quantity</b>	3
<b>Distribution Ports, quantity</b>	648
<b>Fibers per Distribution Cable, quantity</b>	216
<b>Fibers per Feeder Cable, quantity</b>	48
<b>Interface, Input</b>	SC
<b>Interface Feature, Input</b>	APC
<b>Mounting</b>	Pad
<b>Splitter Slots, quantity</b>	48

## Dimensions

<b>Height</b>	1,238.25 mm   48.75 in
<b>Width</b>	1,220.47 mm   48.05 in
<b>Depth</b>	497.33 mm   19.58 in
<b>Cable Length</b>	30.48 m   100 ft
<b>Enclosure Size</b>	Large

## Material Specifications

<b>Finish</b>	Powder coated
<b>Material Type</b>	Aluminum

# FD3-AJ648J00GCBP4

---

## Environmental Specifications

**Environmental Space** Above ground

## Packaging and Weights

**Packaging quantity** 1

**Packaging Type** Pallet

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

