


FD3-AJ864J00JBPP7

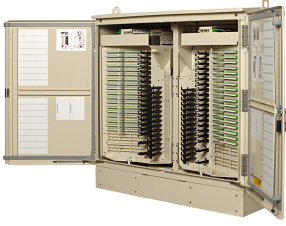

FDH 3000 Fiber Distribution Large Cabinet, 864F, SC/APC, no splitters, dielectric loose tube, 100 ft, 72F

Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	FDH 3000

General Specifications

Access	Front and rear door
Cable Type	Dielectric - Loose Tube
Color	Putty white
Distribution Cables, quantity	6
Distribution Ports, quantity	864
Fibers per Distribution Cable, quantity	144
Fibers per Feeder Cable, quantity	72
Interface, Input	SC
Interface Feature, Input	APC
Mounting	Pad
Splitter Slots, quantity	48

Dimensions

Height	1,238.25 mm 48.75 in
Width	1,220.47 mm 48.05 in
Depth	497.33 mm 19.58 in
Cable Length	30.48 m 100 ft
Enclosure Size	Large

Material Specifications

Finish	Powder coated
Material Type	Aluminum

FD3-AJ864J00JBPP7

Environmental Specifications

Environmental Space Above ground

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

