


FD3-AJ864J2SJBBP7

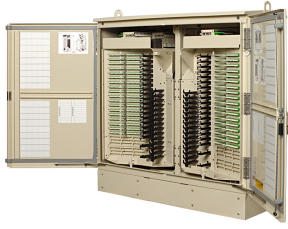

FDH 3000 Fiber Distribution Large Cabinet, 864F, SC/APC, (2) 64-splitter modules, dielectric loose tube, 10 ft, 72F

Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	FDH 3000

General Specifications

Access	Front and rear door
Cable Type	Dry Dielectric - Loose Tube
Color	Putty white
Distribution Cables, quantity	6
Distribution Ports, quantity	864
Fibers per Distribution Cable, quantity	144
Fibers per Feeder Cable, quantity	72
Mounting	Pad
Split Ratio	Symmetrical
Splitter Slots, quantity	48
Splitter Type	1 x 64
Splitter, quantity	2

Dimensions

Height	1,238.25 mm 48.75 in
Width	1,220.47 mm 48.05 in
Depth	497.33 mm 19.58 in
Cable Length	30.48 m 100 ft
Enclosure Size	Large

Material Specifications

Finish	Powder coated
---------------	---------------

FD3-AJ864J2SJBBP7

Material Type Aluminum

Environmental Specifications

Environmental Space Above ground

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

