


# 760109470 | 360G2 Cartridge 12-LC-LS-AQ-PIGTAILS

---

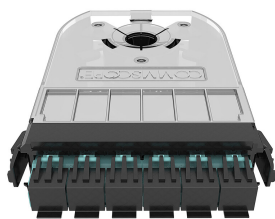

360G2 Multimode OM4 Fiber Cassette 12 LC, with pigtails, iPatch Ready

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber cassette with pigtails
<b>Product Series</b>	G2

## General Specifications

<b>Color, front</b>	Aqua
<b>Intelligence Type</b>	iPatch® ready
<b>Interface, front</b>	LC/UPC
<b>Interface, rear</b>	Stranded pigtail
<b>Shuttered</b>	No
<b>Total Ports, quantity, front</b>	12

## Dimensions

<b>Height</b>	25.908 mm   1.02 in
<b>Width</b>	94.996 mm   3.74 in
<b>Depth</b>	123.012 mm   4.843 in

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM4
<b>Insertion Loss, maximum</b>	0.33 dB

## Environmental Specifications

<b>Qualification Standards</b>	IEC 61753-1   TIA-568.3-D
<b>Safety Standard</b>	CE   CSA   UL

# 760109470 | 360G2 Cartridge 12-LC-LS-AQ-PIGTAILS

---

## Packaging and Weights

**Packaging quantity** 1  
**Weight, net** 0.098 kg | 0.215 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

