


# 760238938 | EHD-SP-24LA-SM-B

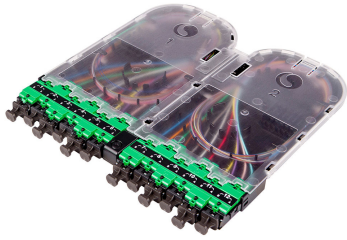

EHD Singlemode Splice Cassette, 24LC/APC with dust plugs and pigtails

## Product Classification

|                              |   |
|------------------------------|---|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   EMEA   Latin America   North America |
| <b>Portfolio</b>             | CommScope®  |
| <b>Product Type</b>          | Fiber cassette with pigtails  |
| <b>Product Series</b>        | EHD   |

## General Specifications

|                               |                   |
|-------------------------------|-------------------|
| <b>Color, front</b>           | Green             |
| <b>Interface, front</b>       | LC/APC            |
| <b>Interface, rear</b>        | Stranded pigtail  |
| <b>Polarity</b>               | Method B Enhanced |
| <b>Shuttered</b>              | No                |
| <b>Total Fibers, quantity</b> | 24                |

## Dimensions

|               |                      |
|---------------|----------------------|
| <b>Height</b> | 11.43 mm   0.45 in   |
| <b>Width</b>  | 169.672 mm   6.68 in |
| <b>Depth</b>  | 163.83 mm   6.45 in  |

## Optical Specifications

|                                |            |
|--------------------------------|------------|
| <b>Fiber Mode</b>              | Singlemode |
| <b>Fiber Type</b>              | G.657.A2   |
| <b>Insertion Loss, maximum</b> | 0.4 dB     |

## Environmental Specifications

# 760238938 | EHD-SP-24LA-SM-B

---

**Qualification Standards** IEC 61753-1 | TIA-568.3-D

**Safety Standard** CE | CSA | UL

## Packaging and Weights

**Included** Single Fusion Splice Protection Sleeves

**Packaging quantity** 1

**Weight, net** 0.181 kg | 0.4 lb

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |



## Included Products

- FST-ACC005 – Fiber Optic Protective Splice Sleeve, 1 package

# FST-ACC005

---



Fiber Optic Protective Splice Sleeve, 1 package

## Product Classification

**Regional Availability** North America  
**Product Type** Fiber protection sleeve

## General Specifications

**Splicing Type** Heat shrink, single fiber fusion

## Environmental Specifications

**Storage Temperature** -40 °C to +85 °C (-40 °F to +185 °F)

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

| Agency     | Classification  |
|------------|---|
| CHINA-ROHS | Below maximum concentration value   |
| REACH-SVHC | Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS       | Compliant   |
| UK-ROHS    | Compliant   |

