


XAGA® 550L Copper Closure, unpressurized, heat shrink, 37 inch sheath opening, 3 inch splice bundle diameter

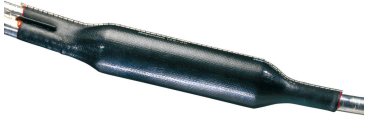

- Full range of closures to suit all copper cable sizes
- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems

OBSOLETE

This product was discontinued on: June 30, 2022

Product Classification

Regional Availability	Latin America North America
Product Type	Unpressurized heat shrink closure
Product Brand	XAGA®
Product Series	XAGA 550L


General Specifications

Application	For use with Polyethylene and metal jacketed cables
Branch-off Clip	To be ordered separately
Cable Capacity, maximum	3
Cable Sealing Type	Hotmelt adhesive
Closure Style	In-line
Color	Black
Mounting	Duct Manhole
Splice Protection Type	Metal canister

Dimensions

Single Cable Diameter, minimum	12.19 mm 0.48 in
Splice Bundle Diameter, maximum	76.2 mm 3 in
Sheath Opening, nominal	939.8 mm 37 in

Dimension Drawing

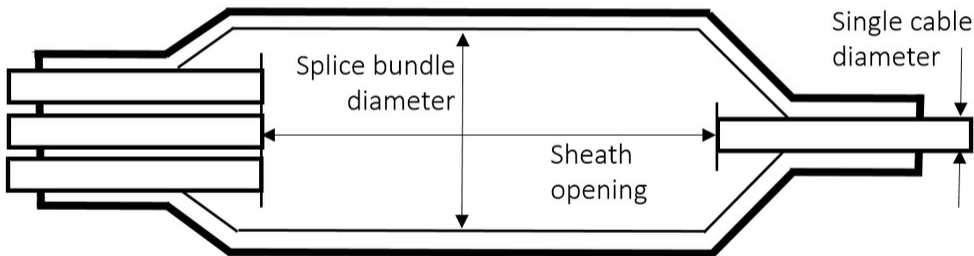

Material Specifications

Material Type Fiber-reinforced multi-layer sealing sleeve

Environmental Specifications

Environmental Space Aerial | Below ground | Buried

Packaging and Weights

Included Abrasive strip | Aluminum closing strip | Aluminum foil | Cleaning tissues | Flexible stainless steel channels | Heatshrinkable sleeve | Metal canister | Shield continuity wire | Underclips | Valve hardware

Packaging quantity 1

Packaging Type Bag | Carton

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

