


FDP-G4PS22072

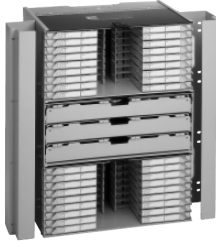

CMT Fiber Termination/Splice Panel, 72, FC/UPC, pre-terminated with pigtailed, singlemode, 13RU, 19 in, putty white

OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

| | |
|------------------------------|-------------------------------|
| Regional Availability | Latin America North America |
| Portfolio | CommScope® |
| Product Type | Fiber patch/splice panel |
| Product Series | CMT |

General Specifications

| | |
|----------------------------------|--------------------------------------|
| Functionality | Patching Splicing |
| Body Style | Symmetrical |
| Color | Putty white |
| Color, front | Putty white |
| Interface, front | FC/UPC |
| Patch Cord Entry Location | Front, left side Front, right side |
| Rack Type | EIA 19 in EIA 23 in |
| Rack Units | 13 |
| Total Ports, quantity | 72 |

Dimensions

| | |
|---------------|----------------------|
| Height | 577.85 mm 22.75 in |
| Width | 482.6 mm 19 in |
| Depth | 304.8 mm 12 in |

Material Specifications

| | |
|---------------|---------------|
| Finish | Powder coated |
|---------------|---------------|

FDP-G4PS22072

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Above maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant |

