


# FDP-G4PS42144

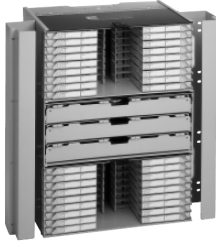

CMT Fiber Termination/Splice Panel, 144, ST/UPC, pre-terminated with pigtails, singlemode, 13RU, 19 in, putty white

## OBSOLETE

This product was discontinued on: March 1, 2018

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch/splice panel
<b>Product Series</b>	CMT

## General Specifications

<b>Functionality</b>	Patching   Splicing
<b>Body Style</b>	Symmetrical
<b>Color</b>	Putty white
<b>Color, front</b>	Putty white
<b>Interface, front</b>	ST/UPC
<b>Patch Cord Entry Location</b>	Front, left side   Front, right side
<b>Rack Type</b>	EIA 19 in   EIA 23 in
<b>Rack Units</b>	13
<b>Total Ports, quantity</b>	144

## Dimensions

<b>Height</b>	577.85 mm   22.75 in
<b>Width</b>	482.6 mm   19 in
<b>Depth</b>	304.8 mm   12 in

## Material Specifications

<b>Finish</b>	Powder coated
---------------	---------------

# FDP-G4PS42144

---

**Material Type** Steel

## Optical Specifications

**Fiber Mode** Singlemode

## Packaging and Weights

**Included** Mounting hardware

**Packaging quantity** 1

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

