


FDP-G4PSP2144

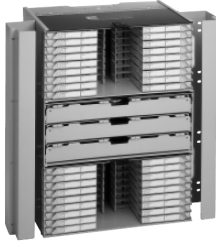

CMT Fiber Termination/Splice Panel, 144, ST/UPC, pre-terminated with pigtails, singlemode, 13RU, 19 in, putty white

OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	CMT

General Specifications

Functionality	Patching Splicing
Body Style	Symmetrical
Color	Putty white
Color, front	Putty white
Interface, front	ST/UPC
Patch Cord Entry Location	Front, left side Front, right side
Rack Type	EIA 19 in EIA 23 in
Rack Units	13
Total Ports, quantity	144

Dimensions

Height	577.85 mm 22.75 in
Width	482.6 mm 19 in
Depth	304.8 mm 12 in

Material Specifications

Finish	Powder coated
---------------	---------------

FDP-G4PSP2144

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant

