

# FL2-C160024JN-1A02

---



FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 24 LC/UPC, multimode, 2RU, 19 in, putty white

## Product Classification

|                              |                               |
|------------------------------|-------------------------------|
| <b>Regional Availability</b> | Latin America   North America |
| <b>Portfolio</b>             | CommScope®                    |
| <b>Product Type</b>          | Fiber patch/splice panel      |
| <b>Product Series</b>        | FL2000                        |

## General Specifications


|   |                                    |
|---|------------------------------------|
| <b>Functionality</b>                    | Patching   Splicing                |
| <b>Adapter Packs Included, quantity</b> | 2                                  |
| <b>Cable Exit Location</b>              | Rear, left side   Rear, right side |
| <b>Color</b>                            | Putty white                        |
| <b>Growth Configuration</b>             | Fully loaded                       |
| <b>Interface, front</b>                 | LC/UPC                             |
| <b>Rack Type</b>                        | EIA 19 in                          |
| <b>Rack Units</b>                       | 2                                  |
| <b>Shelf Movement</b>                   | Hinged                             |
| <b>Splicing Capacity, maximum</b>       | 24                                 |
| <b>Total Ports, quantity</b>            | 24                                 |

## Dimensions

|               |                     |
|---------------|---------------------|
| <b>Height</b> | 88.9 mm   3.5 in    |
| <b>Width</b>  | 482.6 mm   19 in    |
| <b>Depth</b>  | 256.54 mm   10.1 in |

## Ordering Tree

# FL2-C160024JN-1A02

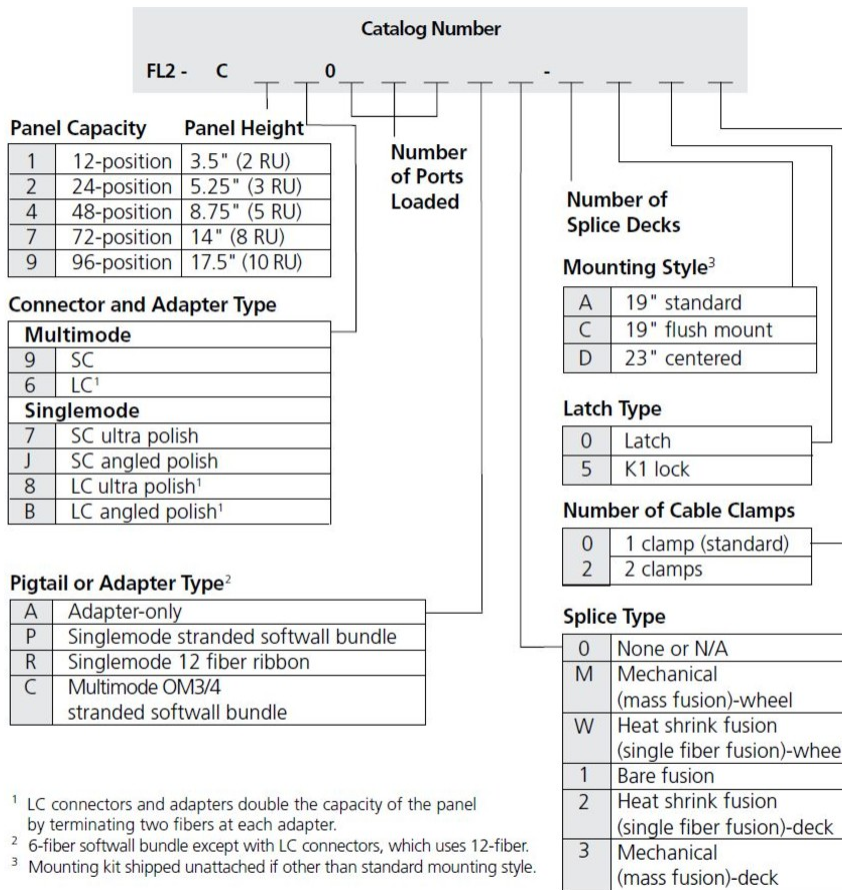

## Material Specifications

|                      |               |
|----------------------|---------------|
| <b>Finish</b>        | Powder coated |
| <b>Material Type</b> | Steel         |

## Optical Specifications

|                   |           |
|-------------------|-----------|
| <b>Fiber Mode</b> | Multimode |
|-------------------|-----------|

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -40 °C to +70 °C (-40 °F to +158 °F) |
| <b>Storage Temperature</b>   | -40 °C to +85 °C (-40 °F to +185 °F) |

## Packaging and Weights

|                           |                   |
|---------------------------|-------------------|
| <b>Included</b>           | Mounting hardware |
| <b>Packaging quantity</b> | 1                 |

# FL2-C160024JN-1A02

---

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant/Exempted

