

FL2-SA80ZA016-CU00

FL2000 Fiber Termination Panel, 24 LC/UPC, singlemode, 1RU, 19 in, putty white, pre-terminated with IFC cable, 16 meters, Stub tail at far end

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel, with IFC cable
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	2
Cable Exit Location	Upward
Cable Stub Type	IFC
Color	Putty white
Growth Configuration	Fully loaded
Interface, front	LC/UPC
Interface, rear	Stub tail
Rack Type	EIA 19 in
Rack Units	1
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	24

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in
Cable Length	16 m 52.493 ft

Ordering Tree

FL2-SA80ZA016-CU00

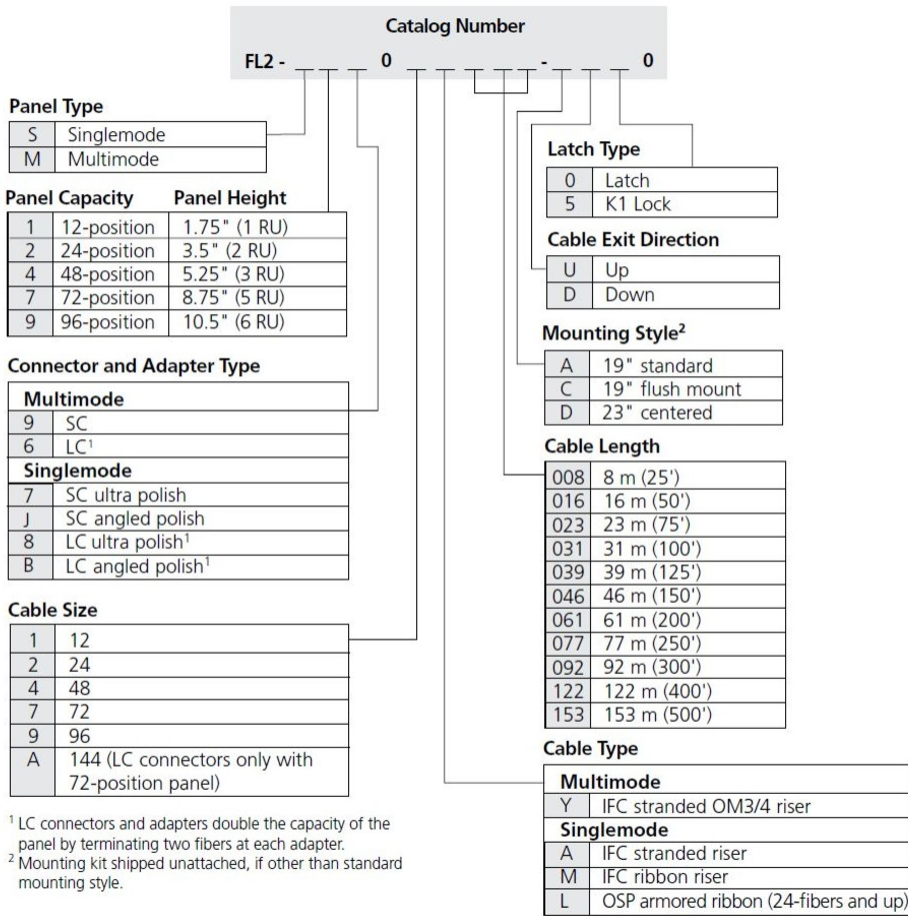

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Packaging quantity 1

FL2-SA80ZA016-CU00

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

