

# TFP-24APRQ5SB3

---

TFP Fiber Optic Adapter Pack, with Singlemode Pigtailed, 6 quad LC UPC adapters, blue

## Product Classification

<b>Regional Availability</b>	Asia   Latin America   North America
<b>Portfolio</b>	NETCONNECT®
<b>Product Type</b>	Fiber adapter pack with pigtailed
<b>Product Series</b>	TFP

## General Specifications


<b>Application</b>	For use with TFP panels
<b>Adapter Color</b>	Blue
<b>Adapters, quantity, front</b>	6
<b>Body Style</b>	Quad   Right orientation
<b>Color, front</b>	Black
<b>Interface</b>	LC/UPC
<b>Pigtail Assembly Type</b>	Color-coded, 900 µm   Pigtail bundle
<b>Pigtails Included, quantity</b>	24
<b>Total Fibers, quantity</b>	24
<b>Total Ports, quantity, front</b>	24

## Dimensions

<b>Height</b>	33.53 mm   1.32 in
<b>Width</b>	176.02 mm   6.93 in
<b>Pigtail Length</b>	3 m   9.843 ft

## Ordering Tree

# TFP-24APRQ5SB3

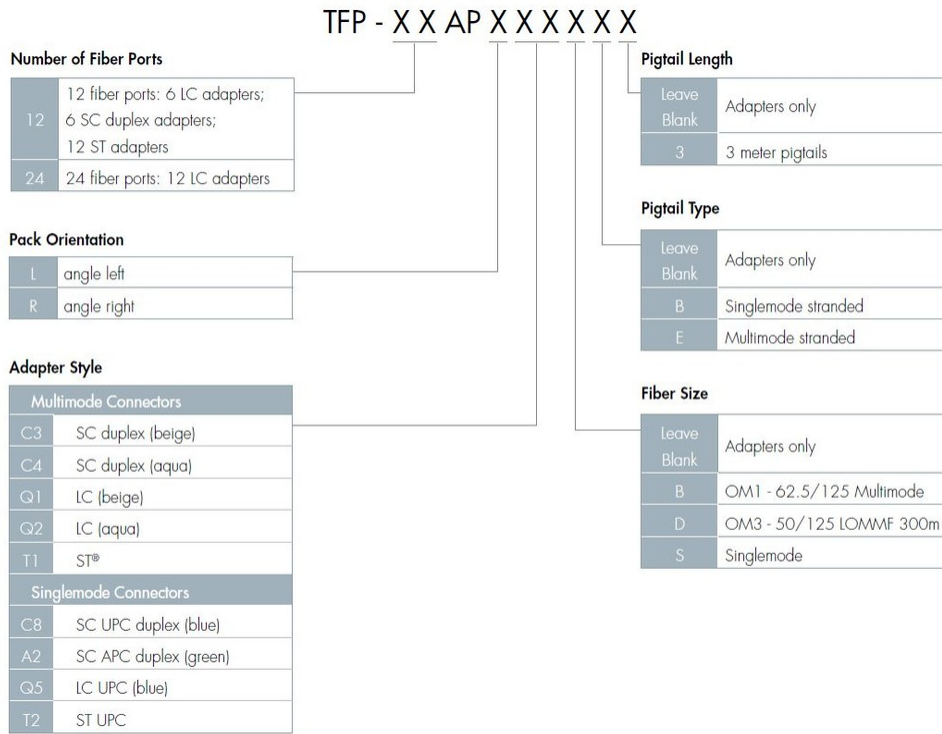

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	OS2
<b>Insertion Loss, maximum</b>	0.3 dB
<b>Return Loss, minimum</b>	55 dB

## Environmental Specifications

<b>Operating Temperature</b>	0 °C to +70 °C (+32 °F to +158 °F)
<b>Storage Temperature</b>	-40 °C to +70 °C (-40 °F to +158 °F)

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Bag   Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value

# TFP-24APRQ5SB3

---

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

