


# F3ZMPMXAM

## Base Product

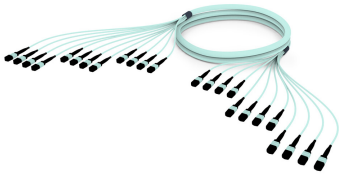

OM3 MPO (Unpinned) to MPO (Pinned), InstaPATCH® 360 Pre-terminated Trunk Cable, 144-Fiber, Low Smoke Zero Halogen B2ca

### OBSOLETE

This product was discontinued on: October 7, 2024

#### Replaced By:

U3XMPMXCM

Ultra Low Loss ULL LazrSPEED® 550 MPO(Unpinned) to MPO(Pinned) Pre-terminated Trunk Cable, MPO12, 144-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX InstaPATCH® 360
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration   Not available in the United States or Canada

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Aqua
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-12/UPC Female
<b>Interface, Connector B</b>	MPO-12/UPC Male
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B (LL)
<b>Fibers per Subunit, quantity</b>	12


# F3ZMPMXAM

**Total Fibers, quantity** 144

## Dimensions

**Breakout Length** 33 in  
**Cable Assembly Length Range (m)** 3 – 999  
**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree

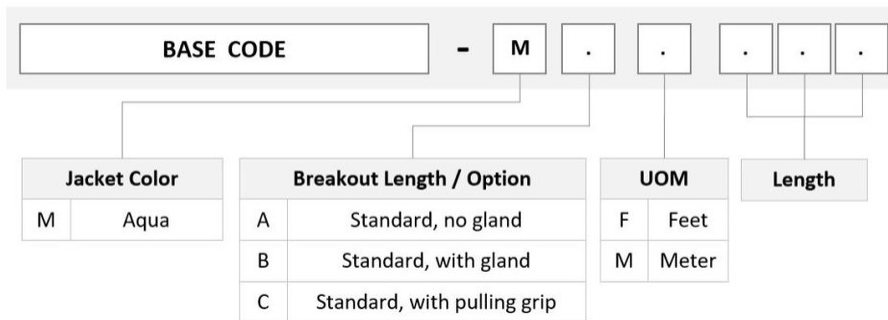

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM3, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**EN50575 CPR Cable EuroClass Fire Performance** B2ca  
**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# F3ZMPMXAM

---

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



## Included Products

- 760239598 N-144-MP-5L-F12AQ/B2 – Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 144 fiber, 12 fiber subunits, Multimode OM3, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating
- 860647047 – MPO12, LOW LOSS, MALE, OM3/4, AQUA, 3mm
- 860647054 – MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm