


FFXLCLC42

Base Product

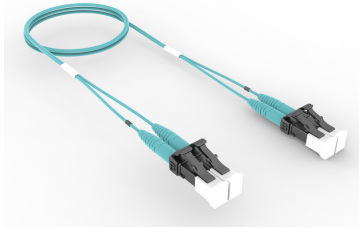

Fiber Patch Cord, LC/UPC/UPC to LC/UPC/UPC, Multimode OM4, 1.6 mm Duplex, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Brand	SYSTIMAX InstaPATCH® 360
Product Series	FFX
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Replacement for MEA Region: 2105027

General Specifications

Color, boot A	Aqua
Color, connector A	Black
Color, boot B	Aqua
Color, connector B	Black
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Pairs, flipped
Total Fibers, quantity	2
Transmission Standards	TIA/EIA-568-C.3

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Diameter Over Jacket	1.6 mm 0.063 in

FFXLCLC42

Ordering Tree



Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



FFXLCLC42

Included Products

- 760021659
N-002-ZC-5K-F16AQ/E
 - 860655461
- Fiber Indoor Cable, LazrSPEED® 1.6 mm Low Smoke Zero Halogen Riser, 2-fiber Zipcord, Multimode OM4, Feet jacket marking, Aqua jacket color, Eca Flame Rating
 - LC/UPC Connector, Multimode, Aqua