


FAWLAUC01

Base Product

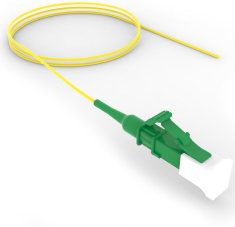

TeraSPEED® LC APC to Unconnectorized, Fiber Pigtail, 0.9 mm Tight Buffer

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	SYSTIMAX InstaPATCH® 360
Product Series	FAW
Ordering Note	Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Green
Color, connector A	Green
Interface, Connector A	LC/APC
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 20
Cable Assembly Length Range (ft)	1 – 66

Ordering Tree

FAWLAUC01

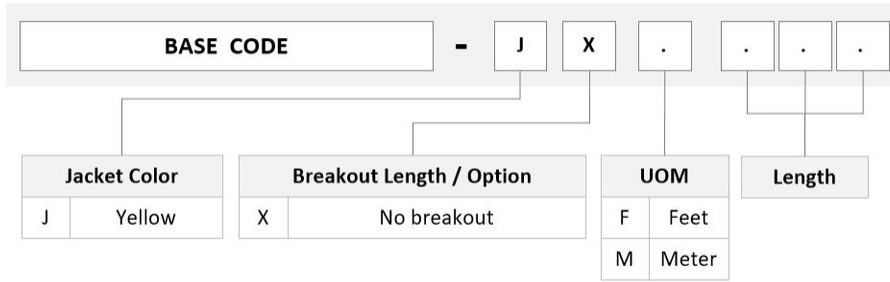

Mechanical Specifications

Cable Retention Strength, maximum 1.00 lb @ 0° | 1.00 lb @ 90°

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Unrated

Packaging and Weights

Packaging quantity 2

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

760038570 – TeraSPEED® 900µm Tight Buffered Fiber
X-TB-8W-YL-F/G

FAWLAUC01

860637438 - LC/APC Connector, Singlemode, Green