


FKXMPMPAL

Base Product

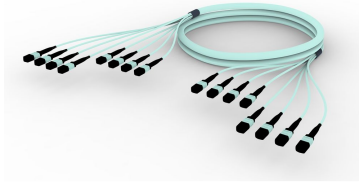

OM4 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Armored Pre-terminated Trunk Cable, 96-Fiber, Low Smoke Zero Halogen

Alternative products available:

UKXMPMPCL

Ultra Low Loss (ULL) LazrSPEED® 550 OM4 MPO12(Unpinned) to MPO12(Unpinned), Armored Pre-terminated Trunk Cable, 48-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China India Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada


General Specifications

Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Armored Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Female
Interface, Connector B	MPO-12/UPC Female
Jacket Color	Aqua
Polarity	Method B (LL)

FKXMPMPAL

Fibers per Subunit, quantity	12
Total Fibers, quantity	96
Dimensions	
Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

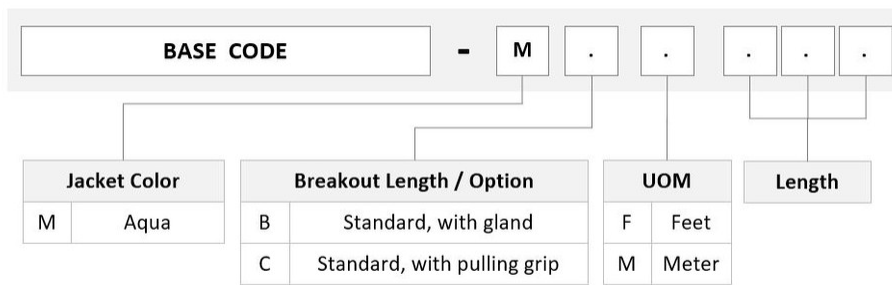

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

FKXMPMPAL

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



Included Products

- 760120097
N-096-MZ-5K-F12AQ – Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM4, 96 fiber multi-unit with 12 fiber subunits, Gel-free, Feet jacket marking, Aqua jacket color
- 860647054 – MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm