


# FKXMPMXAG

## Base Product

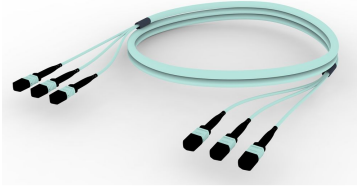

OM4 MPO (Unpinned) to MPO (Pinned), InstaPATCH® 360 Armored Pre-terminated Trunk Cable, 36-Fiber, Low Smoke Zero Halogen

### Alternative products available:

UKXMPMXCG

Ultra Low Loss (ULL) Multimode OM4 MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 36-Fiber, Low Smoke Zero Halogen (LSZH)

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

SYSTIMAX InstaPATCH® 360

### Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada


## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Aqua
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Armored   Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-12/UPC Female
<b>Interface, Connector B</b>	MPO-12/UPC Male
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B (LL)

# FKXMPMXAG

<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	36
<b>Dimensions</b>	
<b>Breakout Length</b>	33 in
<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

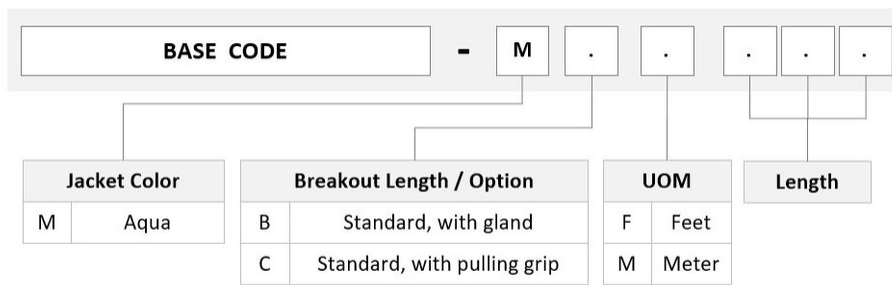

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0 °   4.40 lb @ 90 °
--	---------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM4, LazrSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Dual Rated LSZH/Riser   Indoor

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# FKXMPMXAG

---

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



## Included Products

- 860647047 – MPO12, LOW LOSS, MALE, OM3/4, AQUA, 3mm
- 860647054 – MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
- N-036-MZ-5K-F12 – Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM4, 36 fiber multi-unit with 12 fiber subunits, Feet jacket marking, B2ca flame rating