


FQZMPSCGD

Base Product

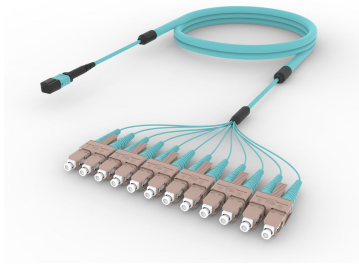

OM3 MPO (Unpinned) to SC/UPC, InstaPATCH® 360 Array Cord, 12-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Aqua
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Female
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Polarity	Method B (LL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions


Cable Assembly Length Range (m)	1 – 305
--	---------

FQZMPSCGD

Cable Assembly Length Range (ft)

1 – 999

Ordering Tree

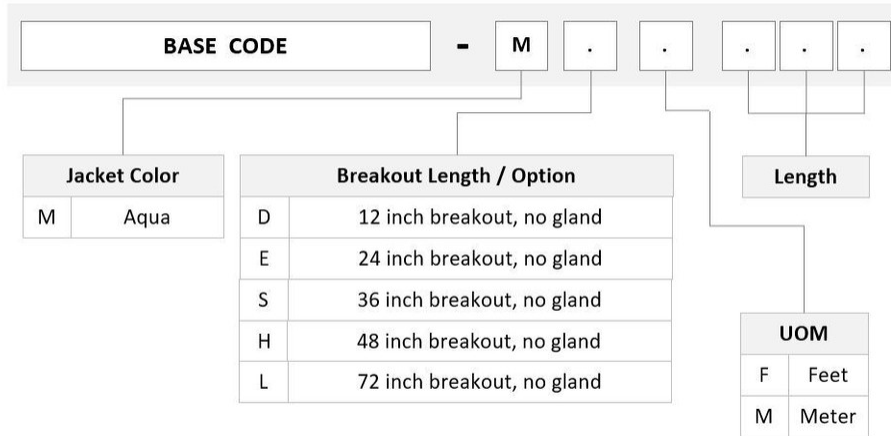

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM3, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

FQZMPSCGD



Included Products

- | | | |
|-------------------|---|--|
| 460125750 | - | LazrSPEED® Pre-Radiused SC Connector for 1.6 mm Fiber Cordage, Duplex, multimode |
| 760074989 | - | Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 12 fiber, Multimode OM3, Feet jacket marking, Aqua jacket color |
| P-012-MP-5L-F30AQ | | |
| 860647054 | - | MP012, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm |