

# FSZL2L2WH

---

## Base Product

LazrSPEED® 300 LC/UPC Keyed Yellow to LC/UPC Keyed Yellow, Distribution Cable, 48-Fiber, Plenum

## Product Classification

<b>Regional Availability</b>	North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber distribution cable assembly
<b>Product Brand</b>	SYSTIMAX InstaPATCH® 360
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters

## General Specifications


<b>Cable Glands</b>	No glands
<b>Color, connector A</b>	Yellow
<b>Color, connector B</b>	Yellow
<b>Construction Type</b>	Distribution, indoor
<b>Interface, Connector A</b>	LC/UPC
<b>Interface Feature, connector A</b>	Keyed
<b>Interface, Connector B</b>	LC/UPC
<b>Interface Feature, connector B</b>	Keyed
<b>Total Fibers, quantity</b>	48

## Dimensions

<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

# FSZL2L2WH

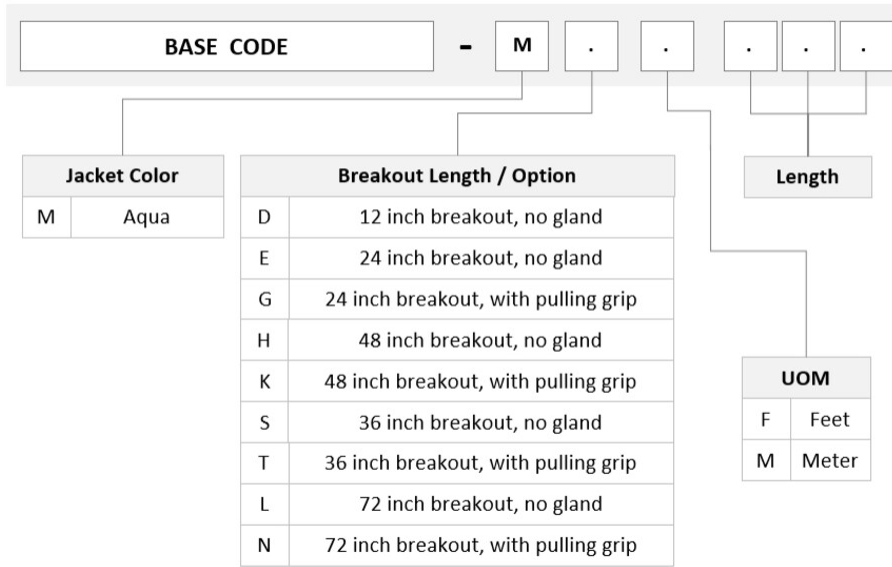

## Mechanical Specifications

**Cable Retention Strength, maximum** 0.50 lb @ 0° | 0.50 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM3, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Plenum

## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

## Included Products

- 760102574 MFC-LCR-09-KYL – LazrSPEED®, OptiSPEED® Pre-Radiused Behind The Wall Keyed LC Connector for 0.9 mm Fiber, multimode, yellow
- P-048-DS-5L-FMU – Fiber indoor cable, LazrSPEED® Plenum Distribution, 48-Fiber Multi-Unit with 12-Fiber Subunits, Multimode OM3, Gel-free, Feet jacket marking