


# U4VMPLCAK

## Base Product

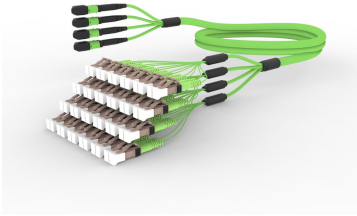

Ultra Low Loss OM5 MPO12 Unpinned to LC/UPC 72-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Low Smoke Zero Halogen

This product will be discontinued on: April 30, 2024

### Replaced By:

U4VMPLCCK

Ultra Low Loss ULL LazrSPEED® 550 OM5 MPO(Unpinned) to LC/UPC Ruggedized fanout Cable, 72-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Ruggedized fanout
<b>Product Brand</b>	SYSTIMAX InstaPATCH® 360   SYSTIMAX ULL
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration   Not available in the United States or Canada

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Lime green
<b>Color, boot B</b>	Lime green
<b>Color, connector B</b>	Beige
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Lime green
<b>Interface, Connector A</b>	MPO-12/UPC Female
<b>Interface, Connector B</b>	LC/UPC
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)

# U4VMPLCAK

**Fibers per Subunit, quantity** 12


**Total Fibers, quantity** 72

## Dimensions

**Cable Assembly Length Range (m)** 3 – 999

**Cable Assembly Length Range (ft)** 7 – 999

## Ordering Tree

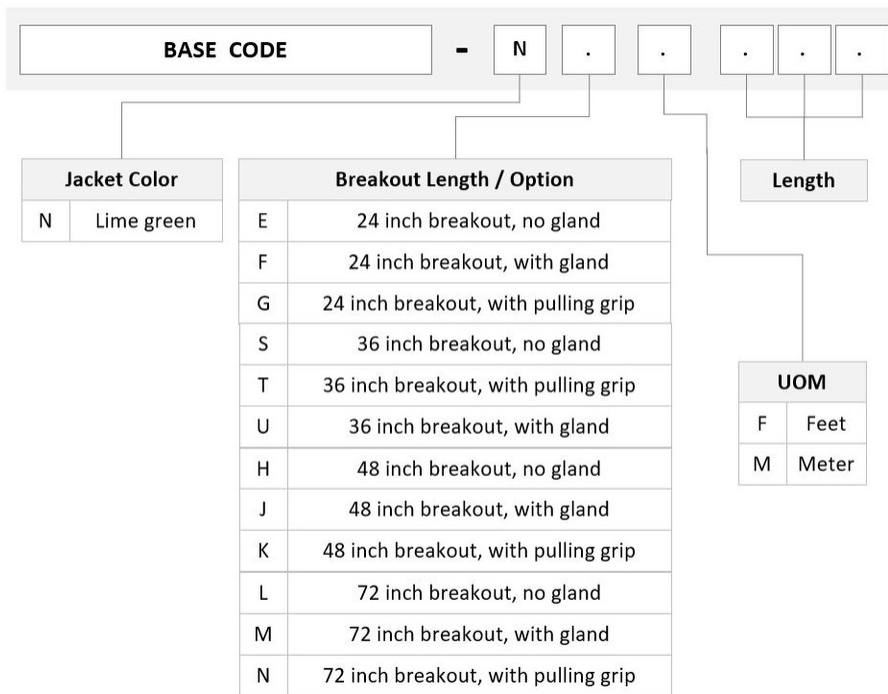

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

# U4VMPLCAK

---

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



## Included Products

760239609 N-072-MP-5G-F12LM/B2	- Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 72 fiber, 12 fiber subunits, Multimode OM5, Gel-free, Feet jacket marking, Lime green jacket color, B2ca Flame rating
860617232	- MP012, ULTRA LOW LOSS, FEMALE, OM5, LIME, 3mm
860637378	- LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode
CS-5G-MP	- LazrSPEED® OM5 WideBand Multimode Fiber