


# U4VMPSCK

## Base Product

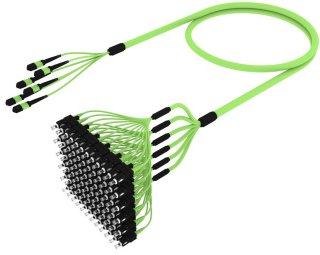

Ultra Low Loss ULL LazrSPEED® 550 OM5 MPO(Unpinned) to SC/UPC Ruggedized fanout Cable, 72-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Europe   Middle East/Africa  |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Ruggedized fanout  |
| <b>Product Brand</b>         | SYSTIMAX ULL   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                       |                         |
|---------------------------------------|-------------------------|
| <b>Color, boot A</b>                  | Black                   |
| <b>Color, connector A</b>             | Black                   |
| <b>Color, boot B</b>                  | Blue                    |
| <b>Color, connector B</b>             | Black                   |
| <b>Construction Type</b>              | Stranded                |
| <b>Furcation Color</b>                | Lime green              |
| <b>Interface, Connector A</b>         | MPO-12/UPC Female       |
| <b>Interface, Connector B</b>         | SC/UPC                  |
| <b>Interface Feature, connector B</b> | ULL                     |
| <b>Jacket Color</b>                   | Lime green              |
| <b>Polarity</b>                       | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b>   | 12                      |
| <b>Total Fibers, quantity</b>         | 72                      |

## Dimensions

|   |          |
|---|----------|
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

# U4VMPSCK

## Ordering Tree

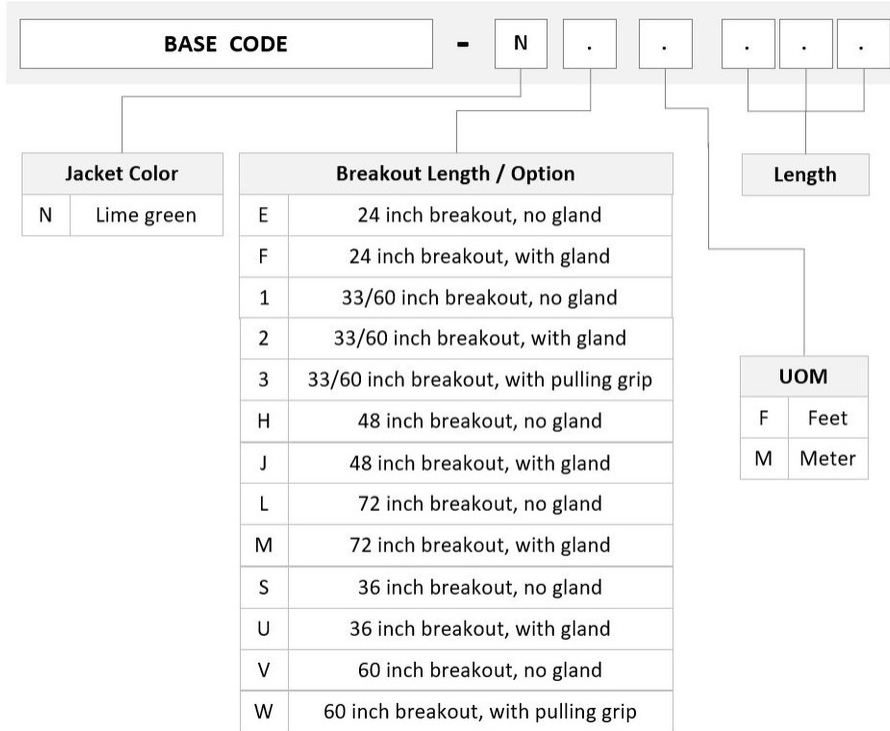

## Optical Specifications

|                   |                 |
|-------------------|-----------------|
| <b>Fiber Mode</b> | Multimode       |
| <b>Fiber Type</b> | OM5, LazrSPEED® |

## Environmental Specifications

|   |  |
|---|--|
| <b>Operating Temperature</b>                        | -10 °C to +60 °C (+14 °F to +140 °F)   |
| <b>EN50575 CPR Cable EuroClass Fire Performance</b> | B2ca                                   |
| <b>Environmental Space</b>                          | Indoor   Low Smoke Zero Halogen (LSZH) |

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

# U4VMPSCCK

---

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

