


# UJVMXMCH

## Base Product

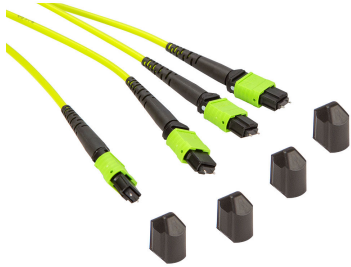

Ultra Low Loss ULL LazrSPEED® 550 OM5 MPO(Pinned) to MPO (Pinned) Pre-terminated Trunk Cable, MPO12, 48-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Black

### Color, connector A

Black

### Color, boot B

Black

### Color, connector B

Black

### Construction Type

Stranded

### Furcation Color

Lime green

### Interface, Connector A

MPO-12/UPC Male

### Interface, Connector B

MPO-12/UPC Male

### Jacket Color

Lime green

### Polarity

Method B Enhanced (ULL)

### Fibers per Subunit, quantity

12

### Total Fibers, quantity


48

## Dimensions

# UJVMXMCH

<b>Breakout Length</b>	33 in
<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

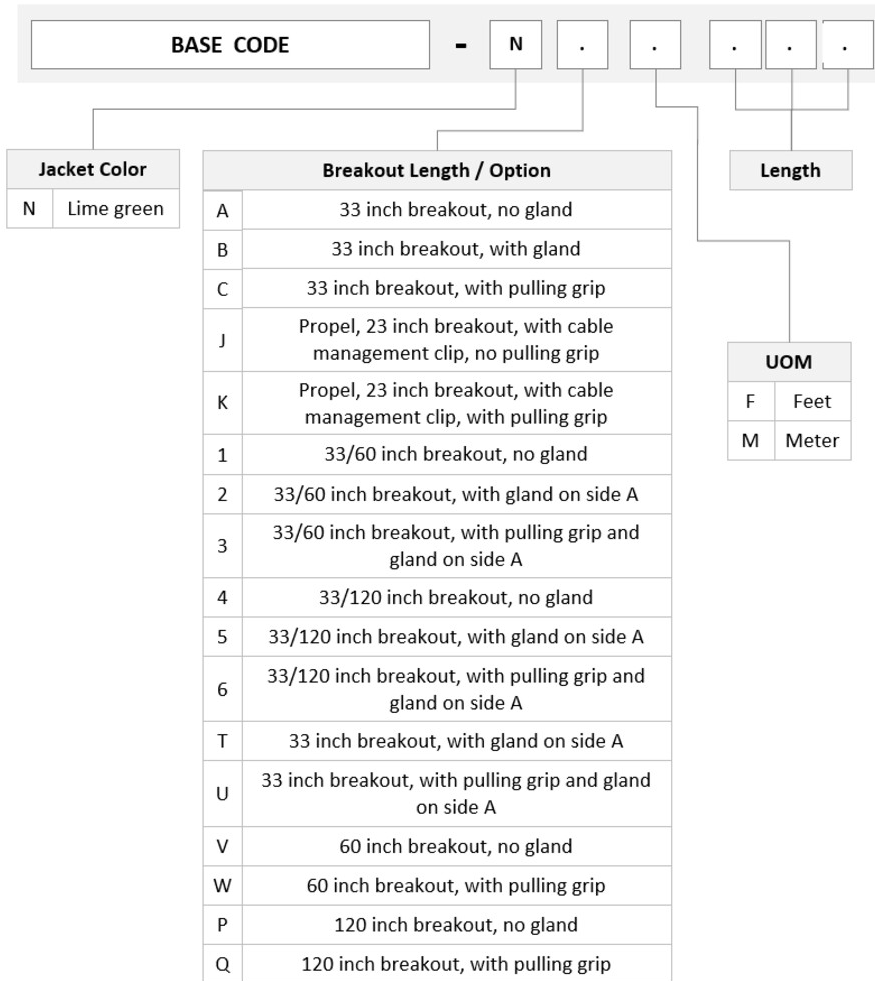

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM5, LazrSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
------------------------------	--------------------------------------

# UJVMXMCH

**EN50575 CPR Cable EuroClass Fire Performance**

Dca

**Environmental Space**

Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

### Agency

### Classification

ANATEL

Compliant

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted



## Included Products

760244158

N-048-MP-5G-F12LM/20T/D

- Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber multi-unit with 12 fiber 2.0mm subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, Dca flame rating

860659008

- MPO12, ULL, MALE, OM5, LIME, 2MM