


# UKGMXXMXDF

## Base Product

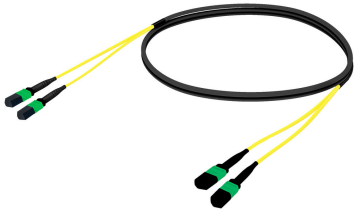

Ultra Low Loss (ULL) Singlemode, MPO12 Pinned to MPO12 Pinned, Fiber Trunk Cable Assembly, 24-Fiber, Indoor/outdoor Armored, Low Smoke Zero Halogen/Riser

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   India   Latin America   Middle East /Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Green
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Armored   Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-12/APC Male
<b>Interface, Connector B</b>	MPO-12/APC Male
<b>Jacket Color</b>	Black
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	24

## Dimensions



# UKGMXMXDF

---

## Included Products

- 760238841  
Z-024-MZ-8G-F12BK – Fiber Indoor/Outdoor cable, Low Smoke Zero Halogen Riser MPO Trunk, interlocking aluminum armored, 24 fiber multi-unit with 12 fiber subunits, Singlemode G.657.A2, Feet jacket marking, Black jacket color
- 860638317 – MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm