


A3XMXMPAD

Base Product

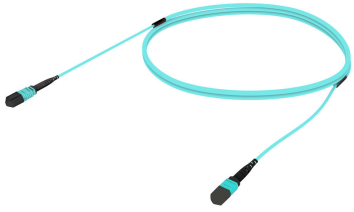

OM4 MPO12 (Pinned) to MPO12 (Unpinned), Fiber Trunk Cable Assembly, 12-Fiber, B2ca, Method A, Low Smoke Zero Halogen

OBSOLETE

This product was discontinued on: April 30, 2024

Replaced By:

A3XMXMPCD

OM4 MPO12 (Pinned) to MPO12 (Unpinned), Fiber Trunk Cable Assembly, 12-Fiber, B2ca, Method A, Low Smoke Zero Halogen

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	MPO-12/UPC Female
Jacket Color	Aqua
Polarity	Method A

A3XMXMPAD

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



Included Products

- 760239372 N-012-MP-5K-F12AQ/B2 – Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber, Gel-free, Multimode OM4, B2ca Flame Rating, Feet jacket marking, Aqua jacket color
- 860366210 – MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
- 860366228 – MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm