


UQGMPLUGD

Base Product

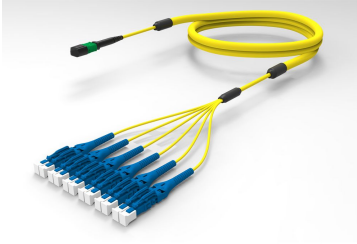

Ultra Low Loss (ULL) Singlemode MPO12 (Unpinned) to LC/UPC Uniboot, Fiber Extension Cable Assembly, 12-Fiber, Plenum

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Europe Latin America Middle East/Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber array cable assembly |
| Product Brand | SYSTIMAX ULL |
| Ordering Note | For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |

General Specifications

| | |
|---------------------------------------|-------------------------|
| Color, boot A | Black |
| Color, connector A | Green |
| Color, boot B | Blue |
| Color, connector B | Blue |
| Construction Type | Stranded |
| Furcation Color | Yellow |
| Interface, Connector A | MPO-12/APC Female |
| Interface, Connector B | LC/UPC |
| Interface Feature, connector B | Uniboot |
| Jacket Color | Yellow |
| Polarity | Method B Enhanced (ULL) |
| Fibers per Subunit, quantity | 12 |
| Total Fibers, quantity | 12 |


Dimensions

UQGMPLUGD

Cable Assembly Length Range (m) 1 – 305

Cable Assembly Length Range (ft) 3 – 999

Ordering Tree

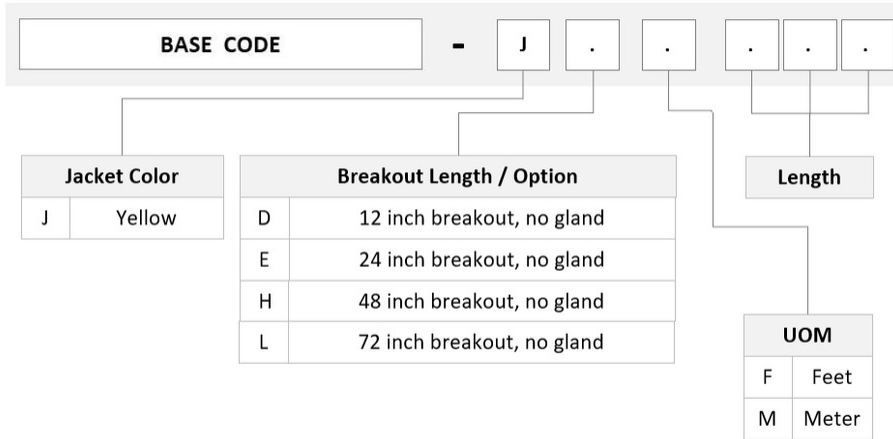

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ANATEL | Compliant |
| CHINA-ROHS | Above maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |

UQGMPLUGD

UK-ROHS

Compliant/Exempted



Included Products

- | | | |
|---------------------------------|---|--|
| 760237964 P-012-MP-8G1-F30YL | - | Fiber indoor cable, Plenum for MPO Light Duty Patchcords, 12 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color |
| 860638318 | - | MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm |
| 860650412 | - | TeraSPEED® LC UniBoot 2.0MM UPC/LC UNIBOOT CONNECTOR KIT |