


UQVQPLCJ8

Base Product

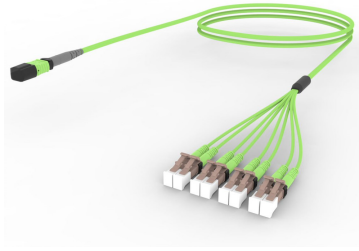

Ultra Low Loss OM5 MPO8 Unpinned to LC/UPC 8-Fiber Plenum Array Cord

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East /Africa | North America

Portfolio

CommScope®

Product Type

Fiber array cable assembly

Product Brand

SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Gray
Color, connector A	Lime green
Color, boot B	Lime green
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/UPC Female
Interface, Connector B	LC/UPC
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	8

Dimensions


Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999

UQVQPLCJ8

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

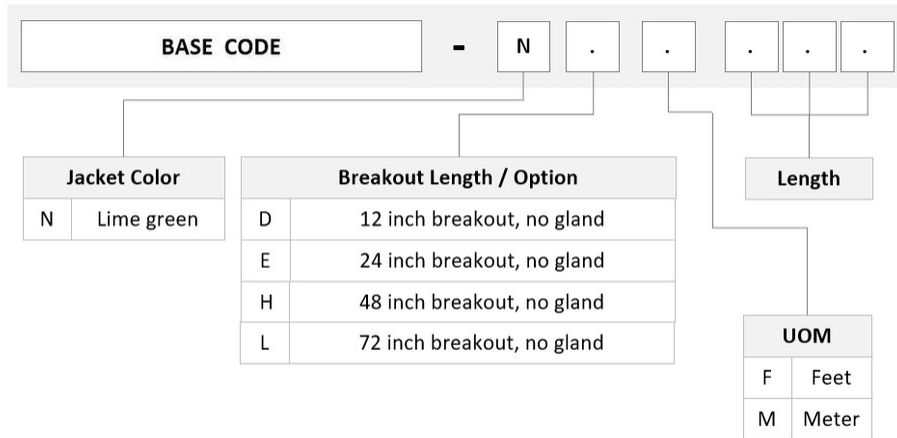

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM5, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space

Indoor | Plenum

Regulatory Compliance/Certifications

Agency

Classification

ANATEL

Compliant

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system



Included Products

UQVQPLCJ8

- | | | |
|-------------------|---|--|
| 760216523 | - | Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 12 fiber, Multimode |
| P-012-MP-5G-F30LM | | OM5, Feet jacket marking, Lime green jacket color |
| 860633311 | - | MPO8, ULTRA LOW LOSS, FEMALE, OM5, LIME, 3mm |
| 860649627 | - | LC/UPC Connector, Multimode, Beige, Short Boot |