


# AJXMXMXCL

## Base Product

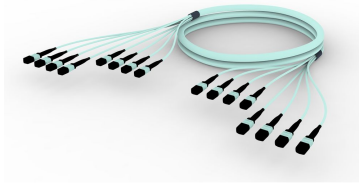

Ultra Low Loss ULL LazrSPEED® 550 MPO(Pinned) to MPO(Pinned)  
Pre-terminated Trunk Cable, MPO12, 96-Fiber, LSZH, 12 fiber PmP 2.0  
mm Dca, Method A

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                     |                 |
|-------------------------------------|-----------------|
| <b>Color, boot A</b>                | Black           |
| <b>Color, connector A</b>           | Black           |
| <b>Color, boot B</b>                | Black           |
| <b>Color, connector B</b>           | Black           |
| <b>Construction Type</b>            | Stranded        |
| <b>Furcation Color</b>              | Aqua            |
| <b>Interface, Connector A</b>       | MPO-12/UPC Male |
| <b>Interface, Connector B</b>       | MPO-12/UPC Male |
| <b>Jacket Color</b>                 | Aqua            |
| <b>Polarity</b>                     | Method A        |
| <b>Fibers per Subunit, quantity</b> | 12              |
| <b>Total Fibers, quantity</b>       | 96              |

## Dimensions

|                        |       |
|------------------------|-------|
| <b>Breakout Length</b> | 33 in |
|------------------------|-------|



## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |



## Included Products

- 760219691  
N-096-MP-5K-F12AQ/20T/D – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 96 fiber multi-unit with 12 fiber 2.0mm subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color, Dca flame rating
- 860659006 – MPO12, ULL, MALE, OM3/4, AQUA, 2MM