

DFJ-6S010



HELIAX® Discrete trunk, 6 single mode, End 1: flex angle DLC with weatherproofing boot, End 2: DLC

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	DFJ
Ordering Note	CommScope® non-standard product

General Specifications


Construction Type	Discrete fiber tail
Interface, Connector A	DLC
Interface Feature, connector A	Nokia boot
Interface Body Style, connector A	Flex angle
Interface, Connector B	DLC
Interface Body Style, connector B	Straight
Jacket Color	Black
Total Fibers, quantity	6

Dimensions

Cable Assembly Length Range (ft)	6 – 50
Diameter Over Jacket	8 mm 0.315 in

Ordering Tree

DFJ-6S010-10

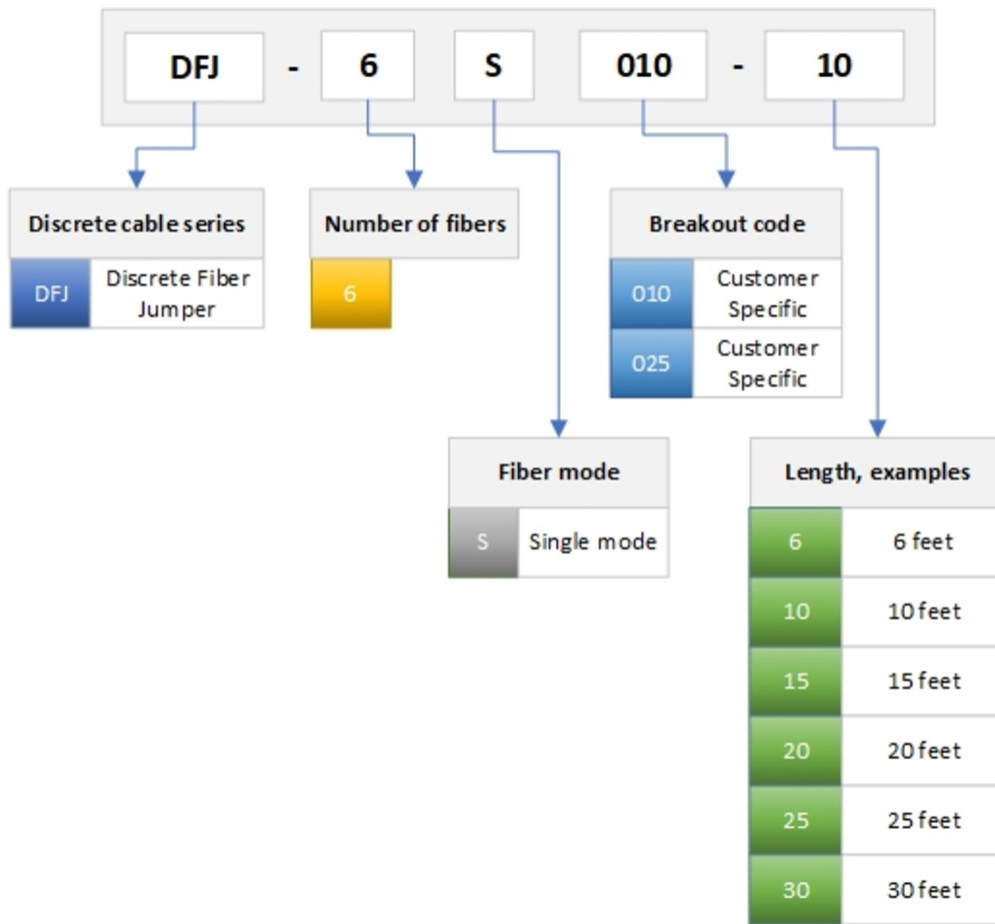

Optical Specifications

Fiber Type	G.657.A2
Insertion Loss, typical note	Insertion loss is measured at 1310 and 1550 nm
Insertion Loss, typical	0.5

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Environmental Space	Outdoor

Packaging and Weights

Cable weight	69 kg/km 46.366 lb/kft
---------------------	--------------------------

Regulatory Compliance/Certifications

Agency	Classification
---------------	-----------------------

DFJ-6S010

CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



* Footnotes

Insertion Loss, typical note Insertion loss is measured at a room temp of +20°C (+68°F)