


FPCFY-SPSC-P-2M

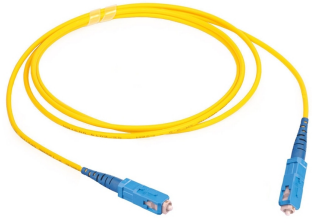

Fiber Optic Patch Cord, Simplex, Singlemode, SC/UPC to SC/UPC, yellow, 2 m

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber patch cord, simplex
Product Series	FPCFY

General Specifications

Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	1
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	SC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Cord Length	2 m 6.562 ft
Diameter Over Jacket	1.7 mm 0.067 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®
Insertion Loss, maximum, connector A	0.2 dB
Insertion Loss, maximum, connector B	0.2 dB

FPCFY-SPSC-P-2M

Return Loss, minimum, connector A	55 dB
Return Loss, minimum, connector B	55 dB

Environmental Specifications

Environmental Space	Plenum
----------------------------	--------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant/Exempted

