


2055664-2 | OCJ-S3-02MASEN-S3

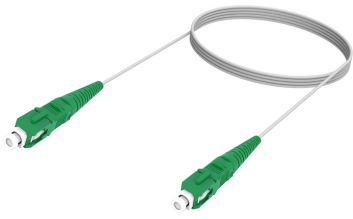

Fiber Optic Patch Cord, Simplex, Singlemode, SC/APC 9° to SC/APC 9°, white, 2 m

Product Classification

Regional Availability	EMEA
Product Type	Fiber patch cord, simplex
Product Series	OCJ

General Specifications

Connector A, quantity	1
Color, boot A	Green
Color, connector A	Green
Connector B, quantity	1
Color, boot B	Green
Color, connector B	Green
Interface, Connector A	SC/APC
Interface Feature, connector A	APC 9°
Interface, Connector B	SC/APC
Interface Feature, connector B	APC 9°
Jacket Color	White
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Cord Length	2 m 6.562 ft
Diameter Over Jacket	0.9 mm 0.035 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A1, TeraSPEED®

Performance Grade	Standard C grade
Insertion Loss, maximum, connector A	0.5 dB
Insertion Loss, maximum, connector B	0.5 dB
Return Loss, minimum, connector A	60 dB
Return Loss, minimum, connector B	60 dB

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Environmental Space	Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



* Footnotes

Performance Grade	Guarantee to meet IEC 61755-1 Random Mating requirement
--------------------------	---