

TFBM7-1



ION®-B Series Extension Unit for Cellular 700

OBSOLETE

Product Classification


Product Type	Extension unit
Product Brand	ION®-B

General Specifications

Note	Detailed Product Specifications are available. Please contact your local CommScope representative.
Power Class	Medium

Dimension Drawing

TFBM7-1

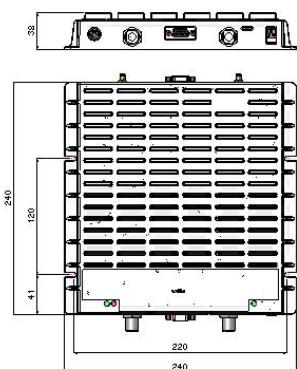

Electrical Specifications

Impedance	50 ohm
License Band	Cellular 700
Voltage Range	85 to 265 Vac

Electrical Specifications, Tx (Downlink)

Operating Frequency Band	728 – 757 MHz (Cellular 700)
---------------------------------	------------------------------

Cabling Drawing

Cabling Drawing 2

Regulatory Compliance/Certifications

TFBM7-1

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- TPSN1/28-80 – Power Supply Adapter ION®-B Series Remote Units, 80 W

TPSN1/28-80



Power Supply Adapter ION®-B Series Remote Units, 80 W

Product Classification

Product Type	Power adapters
Product Brand	ION®-B

General Specifications

Note	Detailed Product Specifications are available. Please contact your local CommScope representative.
-------------	--

Dimension Drawing

Electrical Specifications

Output Power, maximum	80 W
------------------------------	------

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

