


760075069 | M81C Coupler

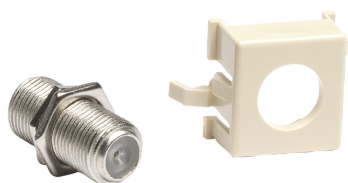

M81C Coaxial Coupler, almond

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Multimedia coupler

General Specifications

Application	Module designed for video applications
Color	Almond
Mounting	Snap-in

Dimensions

Height	17.526 mm 0.69 in
Width	18.542 mm 0.73 in
Depth	12.7 mm 0.5 in

Material Specifications

Material Type	High-impact, flame retardant, thermoplastic
----------------------	---

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	5%–95%, non-condensing
Flammability Rating	UL 94 V-0

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
---------------	-----------------------

760075069 | M81C Coupler

CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

