

UHGLCUCAD

Base Product

Ultra Low Loss TeraSpeed LC/UPC to Unconnectorized Armored Pre-terminated Trunk Cable, 12-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration


General Specifications

Connector A, quantity	12
Color, boot A	Blue
Color, connector A	Blue
Construction Type	Ultra Low Loss (ULL) armored trunk/extension/cross-connect, indoor
Furcation Color	Yellow
Interface, Connector A	LC/UPC
Interface Feature, connector A	ULL
Interface, Connector B	Unterminated
Interface Feature, connector B	ULL
Jacket Color	Yellow
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Breakout Length, connector A	838.2 mm 33 in
Cable Assembly Length Range (m)	1 – 61
Cable Assembly Length Range (ft)	8 – 999

Ordering Tree

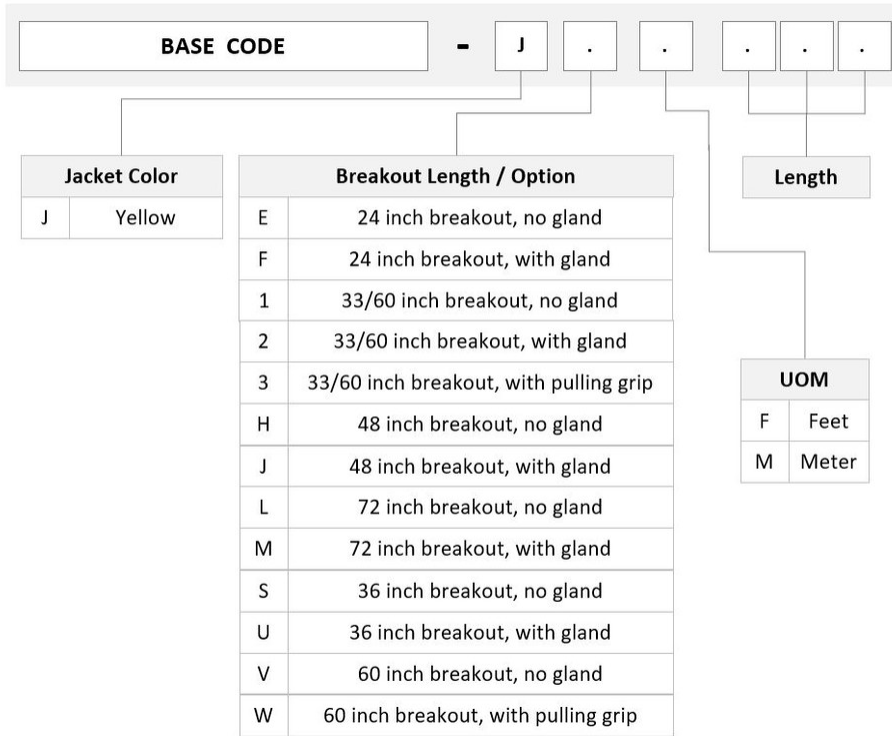

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

Included Products

UHGLCUCAD

- 760245029
P-012-MZ-8G1-F12YL - Fiber indoor cable, Plenum MPO Trunk, interlocking aluminum armored with plenum jacket, 12 fiber, Singlemode G.657.A2/B2, Gel-free, Feet jacket marking, Yellow jacket color
- 860637435 - LC/UPC Connector, Singlemode, Blue, Short Boot