


# 760244850 | FACT-MMDR5H-B

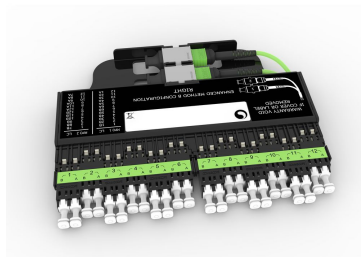

FACT® MPO Module, right sided, LC at front side, 2x12 fiber MPO at rear side, ULL multimode OM5, wiring method B Enhanced

- Offers the same craft-friendly interface for LC and SC connectors as the cabled module
- Allow installers to connect an MPO trunk cable to turn up services in rapid installation applications

## Product Classification

<b>Regional Availability</b>	Asia   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber module
<b>Product Brand</b>	FACT®
<b>Product Series</b>	FACT

## General Specifications

<b>Functionality</b>	Breakout
<b>Application</b>	For Use with FACT NG4 Universal Chassis
<b>Body Style</b>	Right orientation
<b>Color, boot</b>	Black
<b>Color, housing</b>	Black
<b>Color, rear</b>	Lime green
<b>Interface, front</b>	LC/UPC
<b>Interface Feature, front</b>	Duplex
<b>Interface Color, front</b>	Lime green
<b>Interface, rear</b>	MPO
<b>Interface Feature, rear</b>	Female   Key up/up   Unpinned
<b>Interface Color, rear</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Total Fibers, quantity</b>	24
<b>Total Ports, quantity, front</b>	12
<b>Total Ports, quantity, rear</b>	2

# 760244850 | FACT-MMDR5H-B

---

## Dimensions

<b>Height</b>	13.21 mm   0.52 in
<b>Width</b>	159.77 mm   6.29 in
<b>Depth</b>	122.68 mm   4.83 in

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Insertion Loss, maximum</b>	0.4 dB
<b>Insertion Loss, typical</b>	0.32 dB
<b>Return Loss, minimum</b>	27 dB

## Environmental Specifications

<b>Operating Temperature</b>	-5 °C to +40 °C (+23 °F to +104 °F)
<b>Storage Temperature</b>	-5 °C to +50 °C (+23 °F to +122 °F)
<b>Relative Humidity</b>	Up to 85%, non-condensing

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Bag   Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

